

467BF.8 | 467BF - Metric hinged jointed combination wrenches





Standards:

NF ISO 1711-1, NF ISO 691, ISO 1711-1, ISO 691, DIN ISO 1711-1, DIN ISO 691

Description:

- Hinged head ratchet combination wrenches: to reach difficult access nuts.
- Compact ratchet mechanism and reversible by flipping the wrench.
- Increment 5° (6° for dimensions 8 and 9 mm).
- Ring head hinged at 180°.
- Open end head angled at 15°.
- Metric sizes: 8 to 19 mm.
- Presentation: satin chrome finish.

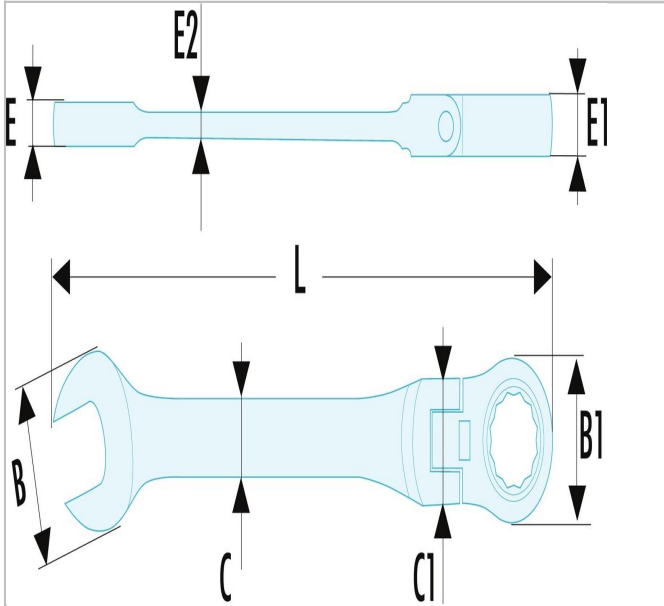

	467BF.8
A [mm]	8.0
Length L [mm]	127.5
Thickness E [mm]	4.6
Thickness E1 [mm]	6.5
Thickness E2 [mm]	3.1
Head Height C [mm]	8.0
Head Width B [mm]	18.6
Head Width B1 [mm]	16.7
Weight [Kg]	0.038