



AR.2X40 | AR - ISORYL screwdrivers for slotted-head screws - milled blade



Description:

- Round blade milled for access to the bottom of the well.
- Finish: polished chromed.

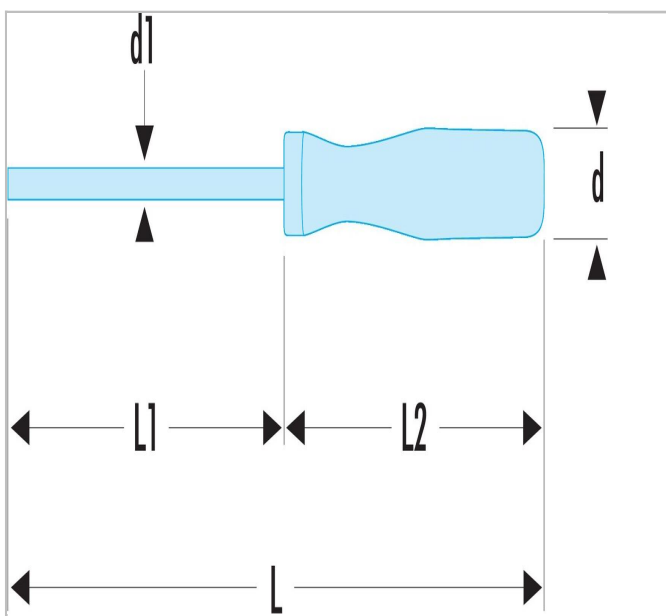

	AR.2X40
Diameter [mm]	16.0
Length L [mm]	110.0
Length L2 [mm]	70.0
Thickness E [mm]	0.4
Weight [g]	13.0
Length L1 [mm]	40.0
Diameter D1 [mm]	2.0