

ATD1X100VE | ATD.VE - PROTWIST® 1,000 Volt insulated screwdrivers for Pozidriv® head screws





Standards:

NF ISO 8764-1, NF ISO 8764-2, NF EN 60900, ISO 8764-1, ISO 8764-2, EN 60900, DIN ISO 8764-1, DIN ISO 8764-2, DIN EN 60900, ASME B107.600

Description:

- For your safety, each screwdriver is tested individually at 10,000 volts for 10 seconds, at the end of the manufacturing cycle.
- 1,000 Volt sheathed round blade.
- Bi-material grip resists to impacts, abrasion, and chemicals.

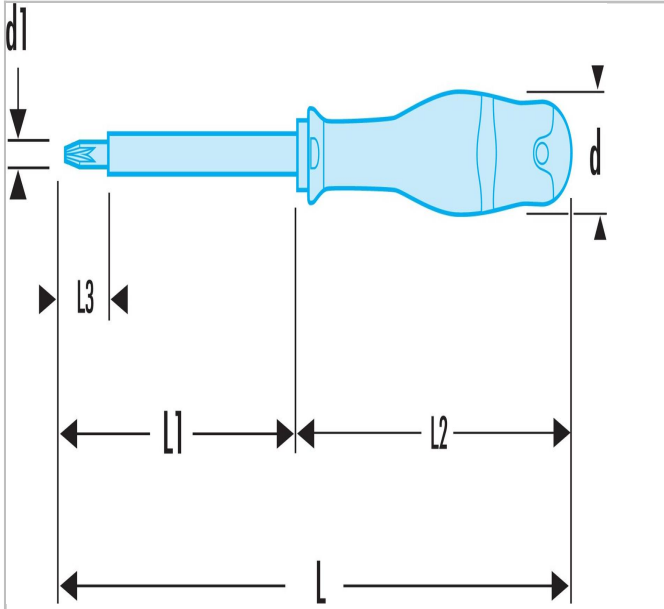

	ATD1X100VE
Diameter [mm]	30.0
Diameter D1 [mm]	4.5
Length L [mm]	209.0
Length L1 [mm]	100.0
Length L2 [mm]	109.0
Length L3 [mm]	18.0
Thickness E [mm]	4.5
Pozidriv Tip Number ["]	PZ1
Weight [g]	77.0