

ATD2X125VE | ATD.VE - PROTWIST® 1,000 Volt insulated screwdrivers for Pozidriv® head screws




Standards:

**NF ISO 8764-1, NF ISO 8764-2,
NF EN 60900, ISO 8764-1, ISO
8764-2, EN 60900, DIN ISO 8764-
1, DIN ISO 8764-2, DIN EN
60900, ASME B107.600**

Description:

- For your safety, each screwdriver is tested individually at 10,000 volts for 10 seconds, at the end of the manufacturing cycle.
- 1,000 Volt sheathed round blade.
- Bi-material grip resists to impacts, abrasion, and chemicals.

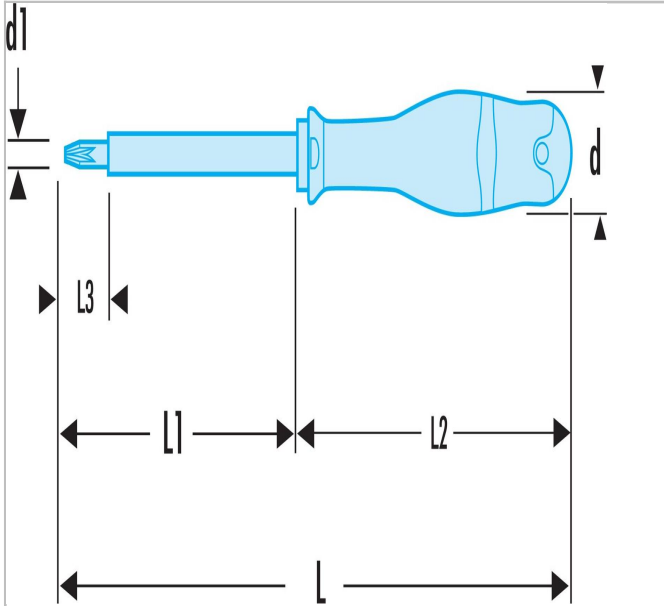

	ATD2X125VE
Diameter [mm]	36.0
Diameter D1 [mm]	6.0
Length L [mm]	245.0
Length L1 [mm]	125.0
Length L2 [mm]	120.0
Length L3 [mm]	18.0
Thickness E [mm]	6.0
Pozidriv Tip Number ["]	PZ2
Weight [g]	127.0