



ATX - PROTWIST® screwdrivers for Torx® screws



Description:

- Compliant with Torx® specifications.
- Inline Hardening Process – +100% Tip Life and +100% Bar Strength.
- Handle Material - Softer for more Comfort and still Chemical Resistant.
- Blade " tri-coating " treatment (Zinc-Nickel-Chromium) - 4x Corrosion Resistance.
- Handle 'Channel' - +10% Torque.
- Laser Marking - gives virtually Permanent Marking.
- CNC tip machining - gives better Screw Fit increasing Torque Transfer and Reducing Wear.

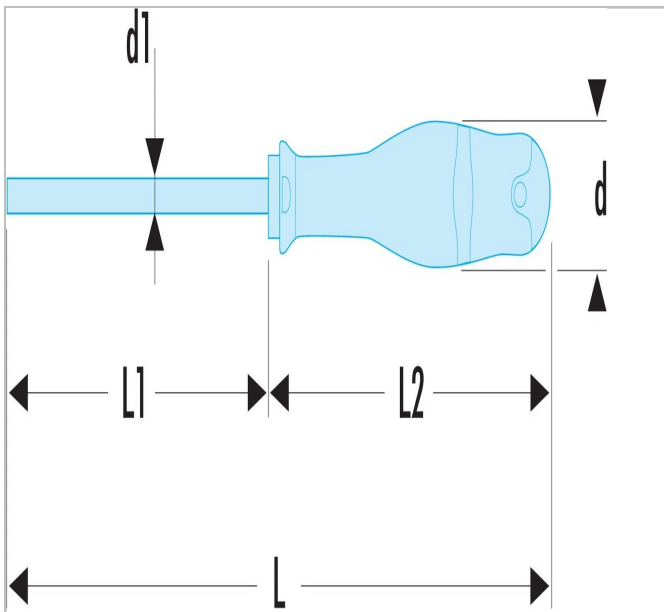

	A [mm]	Diameter [mm]	Diameter D1 [mm]	Length L1 [mm]	Length L [mm]	Length L2 [mm]	Weight [g]	Torx Tip Number ["]
ATX10X75	2.74		3.0	75.0	184.0	109.0	50.0	T10
ATX15X75	3.26		3.5	75.0	184.0	109.0	61.0	T15
ATX20X100	3.84		4.0	100.0	220.0	120.0	67.0	T20
ATX20X150	3.84	36.0	4.0	150.0	270.0	120.0	73.0	T20
ATX25X100	4.4		5.0	100.0	220.0	120.0	113.0	T25
ATX27X100	4.96		5.5	100.0	220.0	120.0	113.0	T27
ATX30X125	5.49		6.0	125.0	245.0	120.0	126.0	T30
ATX40X150	6.6	40.0	7.0	150.0	275.0	125.0	173.0	T40
ATX6X50	1.65		2.5	50.0	144.0	94.0	20.0	T6
ATX7X50	1.97		2.5	50.0	144.0	94.0	20.0	T7
ATX8X50	2.3		2.5	50.0	153.0	103.0	35.0	T8
ATX9X75	2.48		3.0	75.0	178.0	103.0	45.0	T9