

R.240A | 1/4" universal joint





Standards:

NF ISO 3316, ISO 3316, DIN 3123, ASME B107.10

Description:

- Spring-stiffened joints. Stays in position when reaching for fasteners.
- Finish: bright chrome.

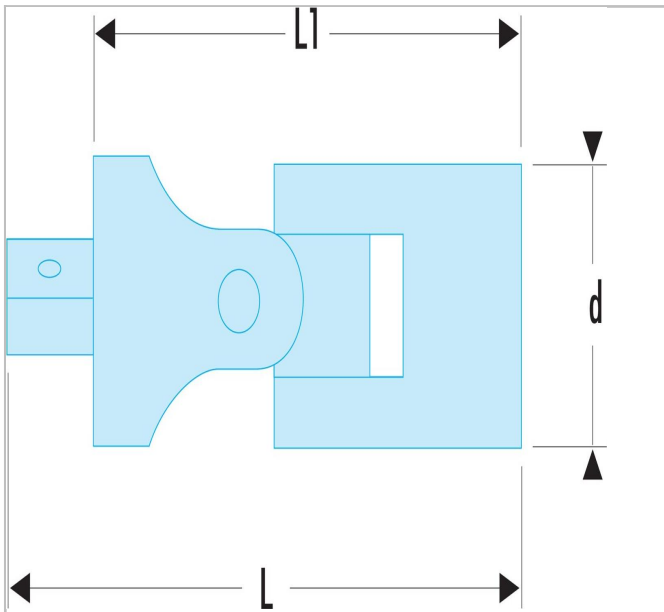

	R.240A
Length L [mm]	33.0
Diameter [mm]	13.0
Weight [Kg]	0.02
Length L1 [mm]	25.0