

S.24 | S - 1/2" metric 12-point sockets




Standards:

NF ISO 2725-1, NF ISO 1711-1,
ISO 2725-1, ISO 1711-1, DIN
3124, ASME B107.5

Description:

- OGV® profile: more powerful tightening, preserves fasteners.
- Finish: bright chrome.
- Supplied on metal rack. Ref S.40E (8 --> 16 mm) and Ref S.41E (17 --> 24 mm).

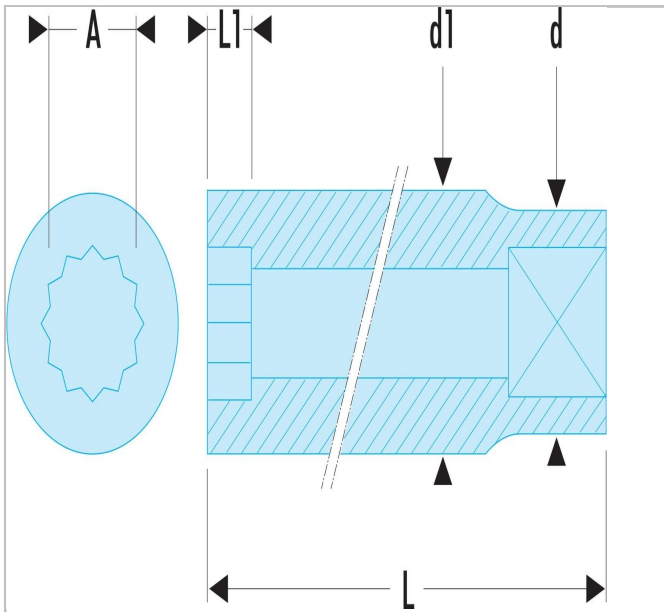

	S.24
A [mm]	24.0
Diameter [mm]	28.7
Diameter D1 [mm]	32.7
Length L [mm]	38.0
Length L1 [mm]	16.5
12-Point [mm]	12
Weight [g]	115.0