

VIDEK

USB System



USB 3.0 A to A Cables

Part No: See Chart

The new SuperSpeed USB 3.0 cables give raw throughput of 4 Gbits. The cables contain two wires for power and ground, two wires for non-SuperSpeed data and four wires for SuperSpeed mode. They are supplied in blue, in fully moulded format in the listed lengths only.

Features & Benefits

- SuperSpeed USB cables up to 10 x faster than standard USB 2.0.
- Manufactured in listed lengths only using, UL20276 USB 3.0 cable.
- 28AWG x 1 Pair with drain/aluminium/mylar, 1x 28AWG Pair, 2 Cores 28AWG.
- Backwards compatible, however, for USB 3.0 speed total USB 3.0 system required.

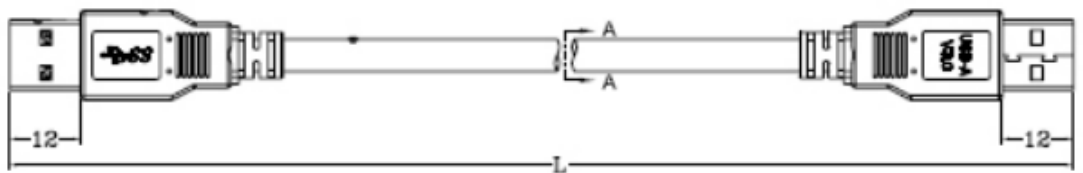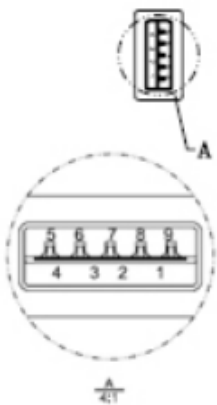

WHITE INK MARKING: USB 3.0 CABLE 28AWG AWM
E139315-F5 STYLE 2725 80° C 30V VW-1

VIDEK

USB System

USB 3.0 A to A Cables

Part No: See Chart

Part Number Chart

| Part Number | Product Description |
|-------------|--|
| 2560A-0.5 | VIDEK USB 3.0 High Speed A to A Cable 0.5Mtr |
| 2560A-1 | VIDEK USB 3.0 High Speed A to A Cable 1Mtr |
| 2560A-2 | VIDEK USB 3.0 High Speed A to A Cable 2Mtr |
| 2560A-3 | VIDEK USB 3.0 High Speed A to A Cable 3Mtr |