

[Update related to COVID-19. Learn More →](#)[Products](#)[Industries](#)[About](#)[Resources](#)[Blog](#)[Contact us](#)[Find A Distributor](#)[Home](#) > [Products](#) > [Cooling Fans](#) > [Harsh/Wet Environment Fans](#) > 11938MA-24L-EA-D0[← Back To Harsh/Wet Environment Fans](#)

Have a question about this product?

[Ask Our Experts →](#)

Harsh/Wet Environment Fans - 11938MA-24L-EA-D0

 


[Get a sample](#)

Resources

[Specification Sheet](#)[Series
Data
Sheet](#)



←

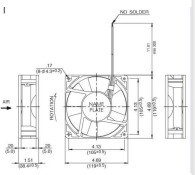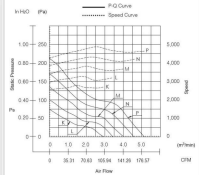

→

Specifications

Category	Harsh/Wet Environment Fans
Part Number	11938MA-24L-EA-D0
Frame Width [mm]	119
Frame Height [mm]	119
Frame Depth [mm]	38

Max. Air Flow [CFM]	122.19
Max. Air Flow [m3 per min]	3.46
Max. Static Pressure [In H2O]	0.41
Max. Static Pressure [Pa]	102
Fan Speed [RPM]	3200
Noise [dB]	49.5
Life Expectancy [L10]	25 degree C 100,000 Hours
Bearing Type	Ball Bearing
Nominal Voltage [V]	24
Operating Voltage - Lower [V]	15
Operating Voltage - Upper [V]	27.6
Current [A]	0.35

Input Power [W]	8.4
Mass [g]	400
IP Rating	IP68/IP69K
Tach / Locked Rotor Output	No
Status	Active

PRODUCTS

[See All Products](#) →

[Find A Distributor](#)

[Find a Sales Representative](#)

INDUSTRIES

[See All Industries](#)

[Automotive](#)

[Industrial](#)

[Medical](#)

[Consumer Technology](#)

[Smart City](#)

[Lighting Innovations](#)

RESOURCES

[See All Resources](#) →

[Application Notes & Whitepapers](#)

[Latest News](#)

[Videos](#)

CONTACT

NMB Technologies Corporation

[\(248\) 919-2250](#)

info@nmbtc.com

Have A Question?

Our precision component experts can help you find the right solutions.

Contact Us Today

Find A Distributor

Find Sales Rep For Fans →

NMB Technologies Corporation © 2021. All Rights Reserved.

[Company](#)

[Careers](#)

[Sitemap](#)

[Privacy
Policy](#)

[Terms of
use](#)