


CREALITY

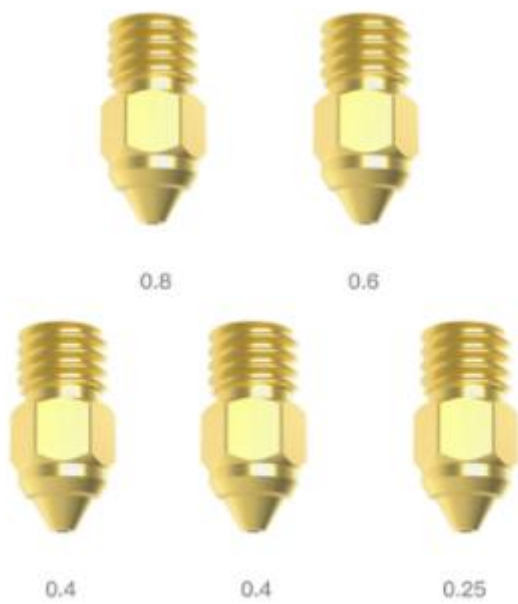

MK-ST Nozzle Kit 5pcs/Set

MFR: 4004020052

MK-ST Nozzle Kit

High Quality Copper Alloy,
Better Printing Effect



MK-ST Nozzle Kit



International Brass

Better thermal conductivity
high hardness



Round aperture

Unimpeded process



Smooth inside

Smooth feeding

Product display

0.25mm*1, 0.4mm*2, 0.6mm*1, 0.8mm*1



0.25



0.4



0.4




0.6



0.8

What's the difference?

Ordinary nozzle VS Copper alloy nozzle of international standard

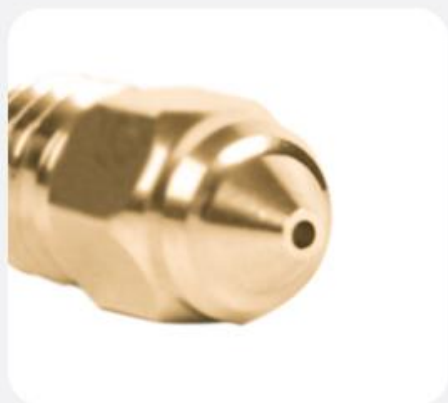

Ordinary nozzle

Models with flaws




Copper alloy nozzle
of international standard

Models with silk and exquisite surface

International Brass, High Quality Performance

International brass, High-quality thermal conductivity,
High hardness, More wear-resistant, Powerful printing effect


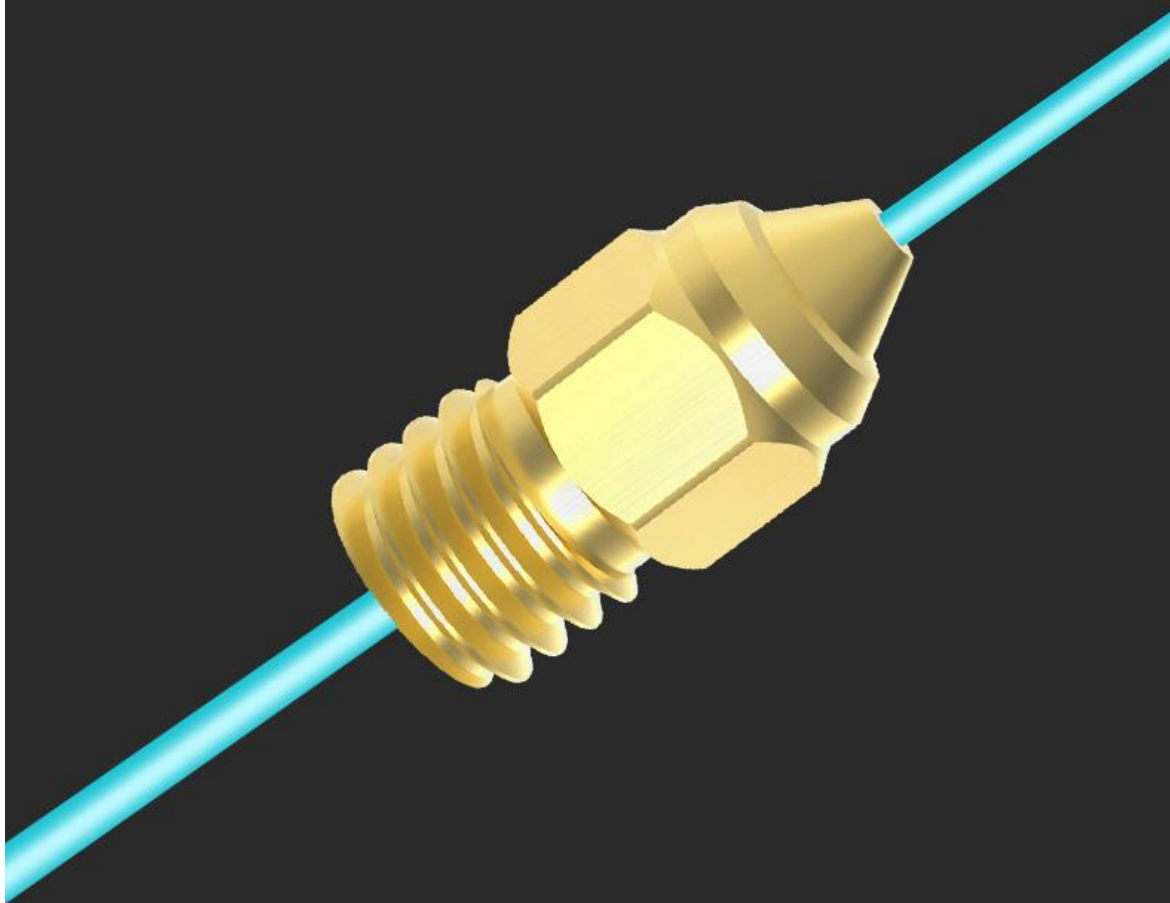


Better Compatibility and Applicability

Works with most FDM printing materials such as PLA, ABS, PETG, TPE, TPU, PC, etc
Compatible with a variety of Creality printers.



Product details

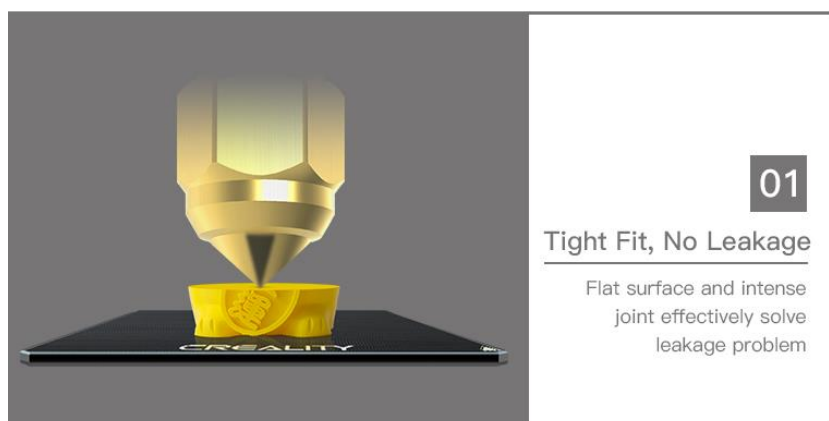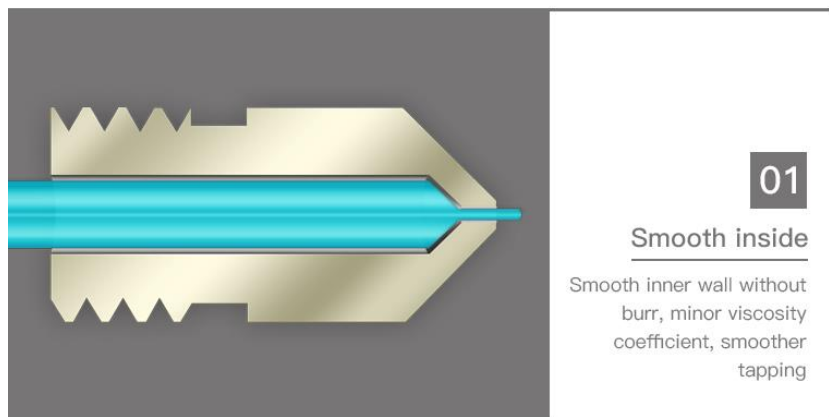

Product Parameters

Product name: MK-ST Nozzle Kit

Aperture diameter: 0.25mm*1 0.4mm*2 0.6mm*1 0.8mm*1

Application: CR-6 SE、CR-6 Max、Ender-6、Ender-3、Ender-3 Pro、
Ender-3S、Ender-3 V2、Ender-3 Max、Ender-5 Pro、
Ender-5 Plus、CR-10、CR-10 V2、CR-10V3、
CR-10Min、CR-10S

Product photograph

