



Connectors > Power Connectors > Circular Power > Circular Power Connectors > CPC EMEA



Connector Product Type: **Housing**

Operating Voltage: **600 VDC**

Connector System: **Wire-to-Wire**

Number of Positions: **3**

Sealable: **No**

[All CPC EMEA \(22\)](#)

Features

Product Type Features

Connector Product Type	Housing
Connector System	Wire-to-Wire
Sealable	No
Connector & Contact Terminates To	Wire & Cable
Connector & Housing Type	Plug
Circular Connector Shell Type	All Plastic

Configuration Features

Reverse Numbering	Without
Number of Positions	3
Number of Power Positions	3
Number of Signal Positions	0

Electrical Characteristics

Operating Voltage	600 VAC
-------------------	---------

Contact Features

Reverse Gender	No
Contact Type	Socket
Contact Protection	With



Mechanical Attachment

Screw & Hole Thread Size	15/16-20 UNEF – 2A
Connector Mounting Type	Cable Mount (Free-Hanging)
Mating Alignment	With
Mating Retention	With
Panel Mount Feature	Without
Mating Alignment Type	Keyed
Mating Retention Type	Threaded Coupling

Housing Features

Body Orientation	Straight
Housing Color	Black
Housing Material	PA 6-6 GF
Circular Connector Shell Size	17

Usage Conditions

Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]
Fluid Resistance	None

Operation/Application

Circuit Application	Power & Signal
Shielded	No

Industry Standards

UL Flammability Rating	UL 94V-0
VDE Tested	No

Packaging Features

Packaging Method	Bag
Packaging Quantity	100

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	




Current ECHA Candidate List: JUL 2021
(219)
Candidate List Declared Against: JAN 2021
(211)
SVHC > Threshold:
Not Yet Reviewed

Halogen Content	Not Yet Reviewed for halogen content
Solder Process Capability	Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Also in the Series | AMP CPC




Circular Connector Adapters(7)




Circular Connector Boots & Strain Relief(6)




Circular Connector Caps & Covers(16)




Circular Connector Hardware(3)




Circular Connector Keying Plugs(2)




Circular Connector Seals(36)

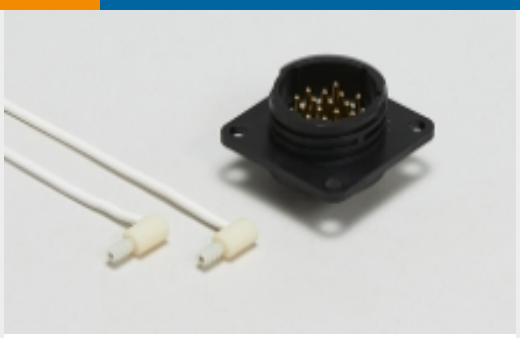


Circular Power Connectors(513)



Insertion & Extraction Tools(1)

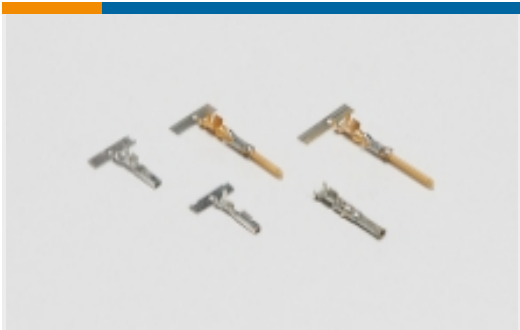

Power Contacts(6)

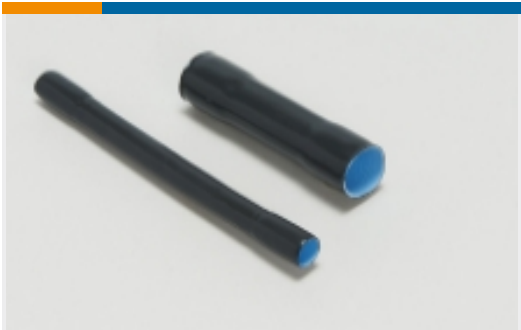

Sealing Sleeves(2)




Unscreened Circular Connector Backshells & Clamps(56)

Customers Also Bought



TE Part #206036-2
CPC SERIES 3

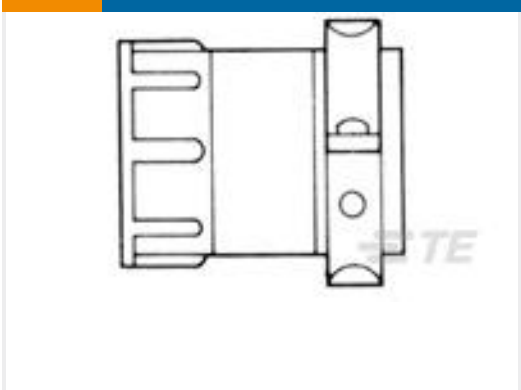

TE Part #206322-9
CABLE CLAMP SIZE 17




TE Part #193991-4
PIN ASSY. TPE XII



TE Part #66259-4
MALE CONTACT ASSY. (L.P.)



TE Part #66740-6
TYPE XII FEMALE CONT (L.P.)

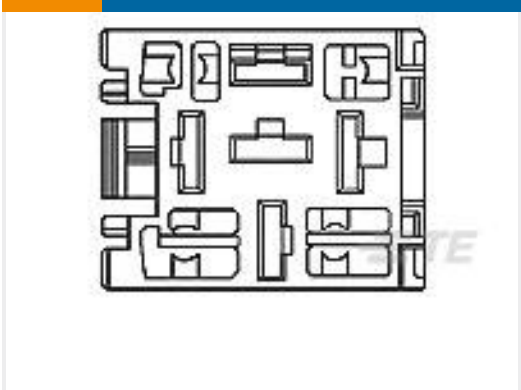

TE Part #280289
MODULAR RELAY CONN.



TE Part #193990-2
SKT ASSY,TYPE XII, #8 AWG



TE Part #66740-2
TYPE XII FEMALE CONT (L.P.)

Documents

Product Drawings

PLUG ASS'Y 17-3STD.SEX SRS 3

English

CAD Files

3D PDF

English

Customer View Model

ENG_CVM_183082-1_A.2d_dxf.zip

English

Customer View Model

ENG_CVM_183082-1_A.3d_igs.zip

English

Customer View Model

ENG_CVM_183082-1_A.3d_stp.zip

English

By downloading the CAD file I accept and agree to the Terms and Conditions of use.



[Agency Approvals](#)

[UL Report](#)

English