
 


HALOGEN LAMP H3 70W/24V

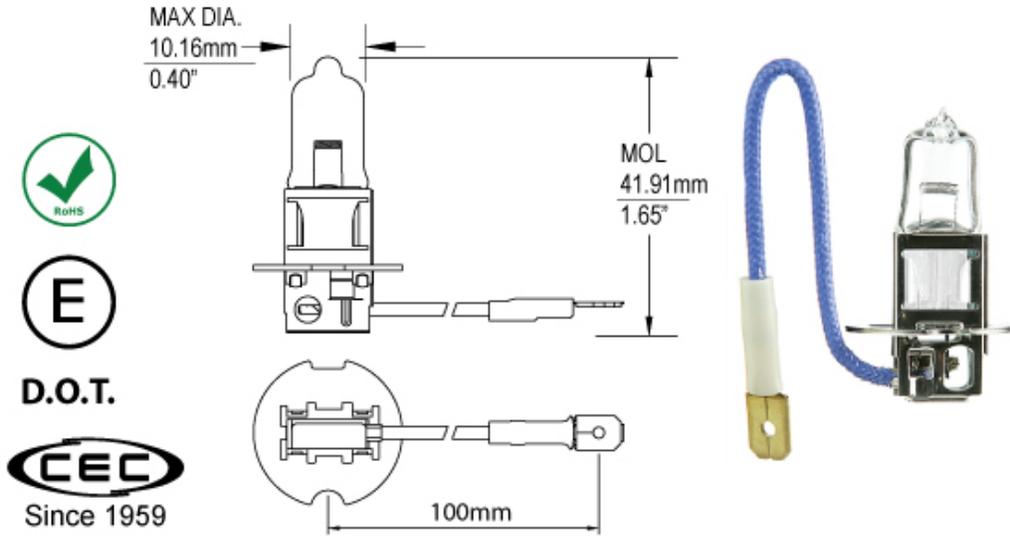

Part #	H3 70W/24V				
Description	T3 1/4 24V 70W PK22s HALOGEN				
Bulb Shape	T3 1/4	Filament	C-6	Base Style	PK
Glass Diameter	.45in/ 11.43mm	Lumens	1750	Base Material	Me
Design Wattage	84	MSCP †	139	RoHS Compliant	Ye
Design Voltage	28	MOL ‡	1.65in/ 41.91mm	Rated Avg Life Hrs	40
Design Amps	2.92	LCL ††	.70in/ 17.78mm	Headlight Socket	
E-Mark	Yes	Drawing Details	H3 70W-24V.pdf	Announcement Sheet	

Click below to see NAFTA & Packaging information



† MSCP (Mean Spherical Candlepower):

Candlepower produced at design volts. Candlepower is increased rapidly with an increase of applied voltage and conversely is reduced rapidly with a reduction of applied voltage.

‡ MOL (Maximum Overall Length):

The overall length of a lamp, from the top of the shell to the bottom of the base.

†† LCL (Light Center Length):

The distance from a reference point, usually the bottom of the lamp base, to the center of the light source.

CERTIFICATES

APPLICATION GUIDES

DOWNLOADS

ABOUT



[List of PDF downloads](#)



[About Us](#)
[Contact Us](#)
[Site Map](#)

CONTACT

CEC INDUSTRIES, LTD
599 Bond Street
Lincolnshire, IL 60069
Phone: (847) 821-1199
Toll Free: (800) 572-4168
Fax: (847) 821-1133

www.cecindustries.com

