


## TWS2 Wideband Splitter H/V

Art. Number 307778

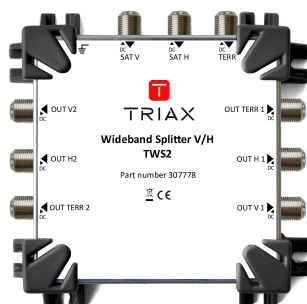

### TWS2 Wideband Splitter H/V

The TWS2 splitter is designed to be used with Wideband systems with Satellite IF frequencies from 290 MHz to 2340 MHz, and Terrestrial frequencies between 5 MHz and 862 MHz.

## Technical Specifications

### ORDER INFORMATION

EAN Number 5702663077782

### CHARACTERISTICS

Type Splitter

### FREQUENCY RANGE

Frequency range SAT | MHz 290...2340 MHz

Frequency range TER | MHz 5...862 MHz

### LOSS

Insertion loss - SAT | dB 4.5 dB

Insertion loss - TER | dB 3.5...4.0 dB

### ELECTRICAL

Impedance |  $\Omega$  75  $\Omega$

### CONNECTORS

Number of inputs 3

Number of outputs 6

### MECHANICAL

Product Depth | mm 50 mm

Dimensions product (H x D x W) | mm 130x130x50 mm

Packaging Depth | m 0.235 m

Packaging Height | m 0.055 m



# TRIAx

connecting the future

## Technical Specifications

Total Weight   kg	0.420 kg
Packaging Width   m	0.255 m
Product Height   mm	130 mm
Net Weight   kg	0.255 kg
Packing QTY	1
Tara Weight   kg	0.165 kg
Packaging Volume   m3	0.003 m3
Product Width   mm	115 mm