


TWT2 Wideband Tap H/V

Art. Number 307779

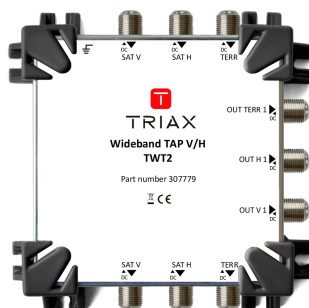

TWT2 Wideband Tap H/V

The TWT2 tap is designed to be used with Wideband systems with Satellite IF frequencies from 290 MHz to 2340 MHz, and Terrestrial frequencies between 5 MHz and 862 MHz.

Technical Specifications

ORDER INFORMATION

EAN Number 5702663077799

CHARACTERISTICS

Type Tap

FREQUENCY RANGE

Frequency range SAT | MHz 290...2340 MHz

Frequency range TER | MHz 5...862 MHz

LOSS

Tap loss SAT | dB 11.0 dB

Tap loss TER | dB 13.0 dB

Through loss - Trunk SAT | dB 2.0 dB

Through loss - Trunk TER | dB 1.5...2.0 dB

ELECTRICAL

Impedance | Ω 75 Ω

CONNECTORS

Number of inputs 3

Number of outputs 6

MECHANICAL

Product Depth | mm 50 mm

Dimensions product (H x D x W) | mm 130x130x50 mm



TRIAx

connecting the future

Technical Specifications

| | |
|-----------------------|----------|
| Packaging Depth m | 0.235 m |
| Packaging Height m | 0.055 m |
| Total Weight kg | 0.410 kg |
| Packaging Width m | 0.255 m |
| Product Height mm | 130 mm |
| Net Weight kg | 0.250 kg |
| Packing QTY | 1 |
| Tara Weight kg | 0.160 kg |
| Packaging Volume m3 | 0.003 m3 |
| Product Width mm | 130 mm |