

ILCANDE14DF026



This 5W retro-fit Integral LED Candle (frosted finish, small screw, white base) delivers a dimmable, cool white light and brightness, similar to a 40W filament bulb. It features high output LEDs and an anti-glare refractor. Ideal for living rooms, dining rooms, bedrooms and hotels, in classic or modern wall or floor/table lamp fittings and chandeliers.

Details

Barcode:	5055788210030
Category:	Lamps
Range Name:	Everyday
Product Type:	Candle
Warranty (Years):	2
CE RoHS:	Yes

Physical Data

Product Length (mm):	112
Product Width (mm):	38
Product Weight (g):	75
Material:	Plastic, Polycarbonate, Nickel plated brass
Base Term:	Small Edison screw
Bulb Base:	E14
Construction:	Aluminium and Plastic heat-sink, Injection moulded diffuser
Globe Finish:	Frosted
Globe Type:	Candle
Bulb Fixing:	Pendant, Chandelier, Wall
Bulb or Luminaire Shape:	Oval

Electrical Data

Power (W):	5
Power Consumption (w):	5
Power Factor:	0.5
Wattage equivalent (W):	40
Amperage (mA):	58
Dimming:	Dimmable
Driver IC Manufacturer:	IWATT


Driver Included:	Yes
Electric Current:	AC
EN:	EN-62560
LVD Certified:	Yes

Light Data

Luminous Flux in Lumens (lm):	500
Luminous efficacy (lm/W):	100
Lumens Range:	470 to 850
Correlated Colour Temperature (CCT) (K):	5000
Colour Temperature:	5000K - Daylight
Colour Temperature Name:	Daylight
Beam Angle:	280
Colour Rendering Index (CRI):	80
Compatible Dimmers:	Varilight JQP401W
Frequency Range (Hz):	50
Instant on (Less than 1 second):	Yes
LED Type:	Surface mounted device (SMD)
Lifetime (hours):	15000
Switching Cycles:	12500

Environment

EN:	EN-62560
LVD Certified:	Yes
CE RoHS:	Yes
Energy Rating:	A+
Hg 0% (Mercury Free):	Yes
IP Rating (Ingress Protection):	IP20
Lowest Operating Temperature (°C):	-20
Maximum Operating Temperature (°C):	40

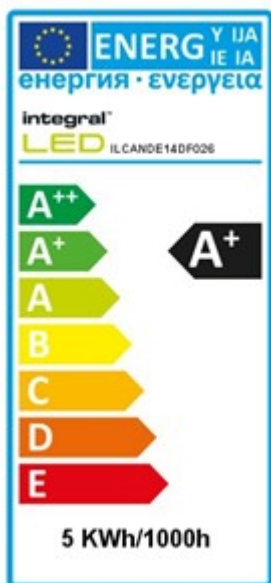

Packaging

Package Weight (g):	100
Package Length (mm):	125

Product Design And Specification Subject To Change Or Modification Without Notice. Image For Illustration Only. E&OE

Package Width (mm):	48
Package Depth (mm):	48
Qty per euro pallet:	1600