



# CorePro LEDspot MV

## CoreProLEDspot 3-35W GU10 830 36D DIM UK

CorePro LEDspots are a perfect fit for spot lighting and deliver warm halogen-like light. They are compatible with most existing fixtures with a GU10 or E14 holder and are designed as a retrofit replacement for halogen or incandescent spots. LEDlamps deliver huge energy savings and minimize maintenance cost.

### Product data


<b>General Information</b>		<b>Wattage equivalent</b>	
Cap base	GU10 [ GU10]	35 W	
EU RoHS compliant	Yes	<b>Starting time (nom.)</b>	
Nominal lifetime (nom.)	15000 h	0.5 s	
Switching cycle	50,000X	<b>Warm-up time to 60% light (nom.)</b>	
<b>Light Technical</b>		0.8	
Colour Code	830 [ CCT of 3,000 K]	<b>Voltage (Nom)</b>	
Beam Angle (Nom)	36 °	220-240 V	
Luminous flux (nom.)	230 lm	<b>Temperature</b>	
Luminous intensity (nom.)	500 cd	<b>T-Case maximum (nom.)</b>	
Colour designation	White (WH)	65 °C	
Correlated Colour Temperature (Nom)	3000 K	<b>Controls and Dimming</b>	
Luminous efficacy (rated) (nom.)	76.00 lm/W	<b>Dimmable</b>	
Colour consistency	<6	Yes	
Colour rendering index (nom.)	80	<b>Mechanical and Housing</b>	
LLMF at end of nominal lifetime (nom.)	70 %	<b>Bulb shape</b>	
Luminous flux in 90° cone (rated)	230 lm	PAR16 [ PAR 2 inch]	
<b>Operating and Electrical</b>		<b>Approval and Application</b>	
Input frequency	50 to 60 Hz	<b>Energy Efficiency Class</b>	
Power (Rated) (Nom)	3 W	F	
Lamp current (nom.)	18 mA	<b>Suitable for accent lighting</b>	
		Yes	
		<b>Energy consumption kWh/1,000 hours</b>	
		3 kWh	
		391910	
		<b>Product Data</b>	
		<b>Full product code</b>	
		871869672135301	

CorePro LEDspot MV

Order product name	CoreProLEDspot 3-35W GU10 830 36D DIM UK
EAN/UPC – product	8718696721353
Order code	72135301
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10

SAP material	929002068299
SAP net weight (piece)	0.048 kg



Dimensional drawing

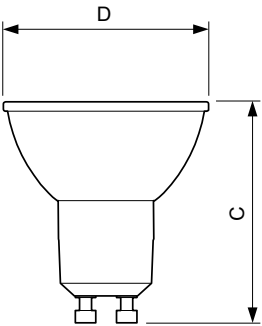

GU10 230V3W-35W250lm36D3000KDim15khrs


Product	D	C
CoreProLEDspot 3-35W GU10 830 36D DIM UK	50 mm	54 mm

Photometric data

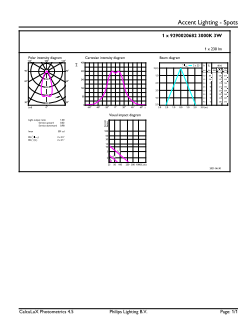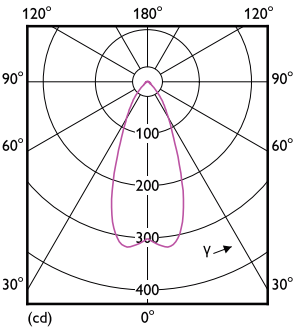

LEDspots Corepro SLR 3W PAR16 GU10 830 36D-LDD


LEDspots Corepro SLR 3W PAR16 GU10 830 36D-ADL

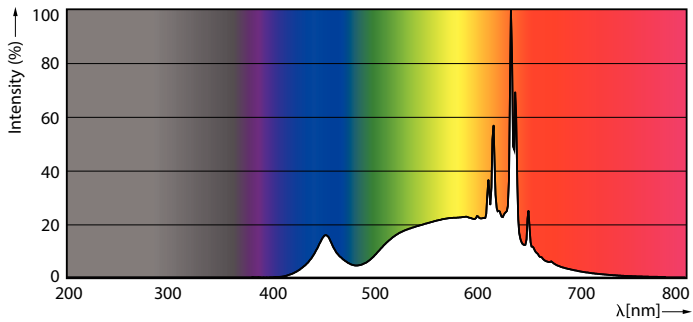


LEDspots Corepro SLR 3W PAR16 GU10 830 36D-POC

CorePro LEDspot MV

Lifetime

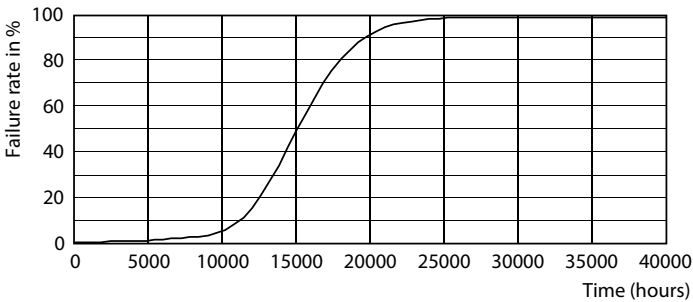

15K LED

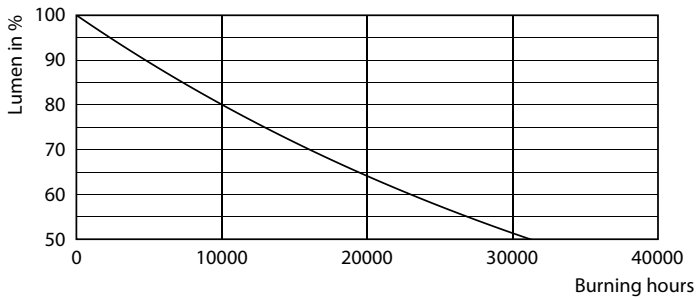

15K LMP

