



CorePro LEDspot MV

Corepro LEDspot 4.6-50W GU10 865 36D UK

CorePro LEDspots are a perfect fit for spot lighting and deliver warm halogen-like light. They are compatible with most existing fixtures with a GU10 or E14 holder and are designed as a retrofit replacement for halogen or incandescent spots. LEDlamps deliver huge energy savings and minimize maintenance cost.

Product data


General Information			
Cap base	GU10 [GU10]	Wattage equivalent	50 W
EU RoHS compliant	Yes	Starting time (nom.)	0.5 s
Nominal lifetime (nom.)	15000 h	Warm-up time to 60% light (nom.)	0.5 s
Switching cycle	50,000X	Power factor (nom.)	0.5
		Voltage (Nom)	220-240 V
Light Technical		Temperature	
Colour Code	865 [CCT of 6,500 K]	T-Case maximum (nom.)	80 °C
Beam Angle (Nom)	36 °	Controls and Dimming	
Luminous flux (nom.)	390 lm	Dimmable	No
Luminous intensity (nom.)	770 cd	Mechanical and Housing	
Colour designation	Cool Daylight	Bulb shape	PAR16 [PAR 2 inch]
Correlated Colour Temperature (Nom)	6500 K	Approval and Application	
Luminous efficacy (rated) (nom.)	84.00 lm/W	Energy Efficiency Class	F
Colour consistency	<6	Suitable for accent lighting	Yes
Colour rendering index (nom.)	80	Energy consumption kWh/1,000 hours	5 kWh
LLMF at end of nominal lifetime (nom.)	70 %		391860
Luminous flux in 90° cone (rated)	390 lm	Product Data	
Operating and Electrical		Full product code	871869672841301
Input frequency	50 to 60 Hz		
Power (Rated) (Nom)	4.6 W		
Lamp current (nom.)	39 mA		

CorePro LEDspot MV

Order product name	Corepro LEDspot 4.6-50W GU10 865 36D UK
EAN/UPC – product	8718696728413
Order code	72841301
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10

SAP material	929001218399
SAP net weight (piece)	0.038 kg


Dimensional drawing

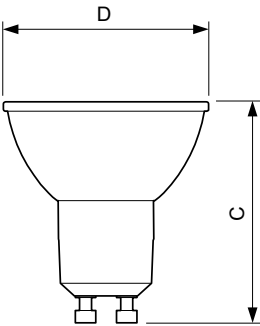


GU10 230V 4W-35W 260lm 100D 4000K GU10ND

Product	D	C
Corepro LEDspot 4.6-50W GU10 865 36D UK	50 mm	54 mm

Photometric data

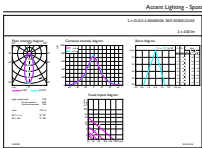


General Information 11 Phot Lighting 11 Page 107

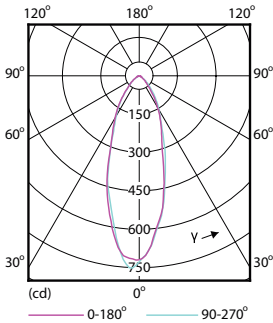

CorePro LEDspotMV 50W GU10 865 36D

CorePro LEDspotMV 50W GU10 830 36D CLA

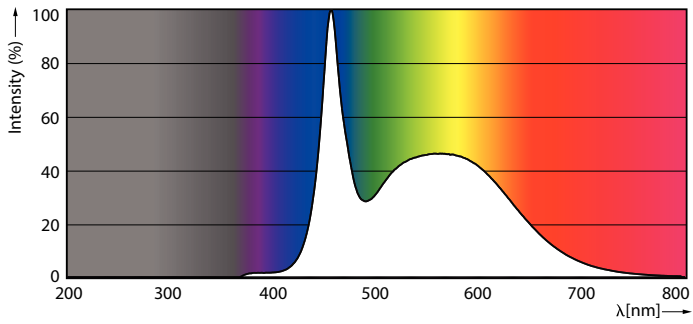


CorePro LEDspotMV 50W GU10 865 36D

CorePro LEDspot MV

Lifetime



CLA LEDspotMV 50W GU10 827 36D ND

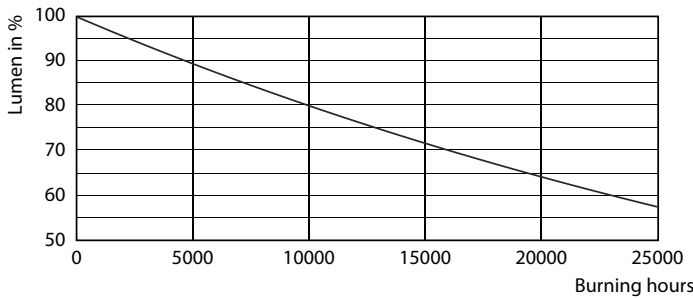

CLA LEDspotMV 50W GU10 827 36D ND

