



CorePro LEDcapsule MV



CorePro LEDcapsule 2-25W ND G9 827

This single-ended mains-voltage capsule for G9-base luminaires delivers directional light, making it a true alternative to halogen capsule lamps. It is particularly suitable for task lighting in shops, hotels and restaurants, and ideal for desk lamps and cabinet lighting. Compatible with existing fixtures with G9 holders and designed for retrofit replacement of halogen capsules, CorePro LEDcapsule delivers huge energy savings and minimizes maintenance costs, without any compromise on light quality.

Product data


General Information		Operating and Electrical	
Cap base	G9 [G9]	Input frequency	50 to 60 Hz
EU RoHS compliant	Yes	Power (Rated) (Nom)	2 W
Nominal lifetime (nom.)	15000 h	Lamp current (nom.)	20 mA
Switching cycle	8,000X	Wattage equivalent	25 W
	Sphere	Starting time (nom.)	0.5 s
		Warm-up time to 60% light (nom.)	0.5 s
		Power factor (nom.)	0.4
		Voltage (Nom)	220-240 V
Light Technical		Temperature	
Colour Code	827 [CCT of 2,700 K]	T-Case maximum (nom.)	78 °C
Beam Angle (Nom)	300 °		
Luminous flux (nom.)	220 lm	Controls and Dimming	
Colour designation	Warm white (WW)	Dimmable	No
Correlated Colour Temperature (Nom)	2700 K		
Luminous efficacy (rated) (nom.)	110.00 lm/W	Mechanical and Housing	
Colour consistency	<6	Lamp Finish	Clear
Colour rendering index (nom.)	80		
LLMF at end of nominal lifetime (nom.)	70 %		

CorePro LEDcapsule MV

Bulb shape	Capsule
Approval and Application	
Energy Efficiency Class	E
Suitable for accent lighting	No
Energy consumption kWh/1,000 hours	2 kWh
	453187
Product Data	
Full product code	871951430389800

Order product name	CorePro LEDcapsule 2-25W ND G9 827
EAN/UPC – product	8719514303898
Order code	30389800
SAP numerator – quantity per pack	1
Numerator – packs per outer box	12
SAP material	929002495202
SAP net weight (piece)	0.012 kg


Dimensional drawing

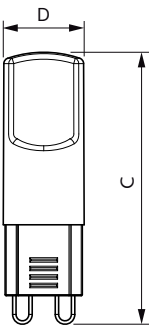


DOB G9 220-240V 2-25W 220lm 2700K ND

Product	D	C
CorePro LEDcapsule 2-25W ND G9 827	14.5 mm	48 mm

Photometric data

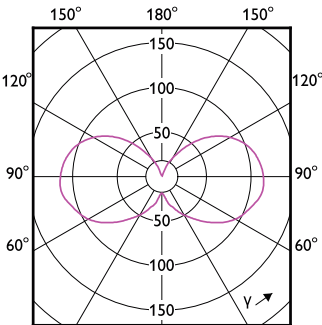


LEDcapsule CorePro 2W G9 827-LDD

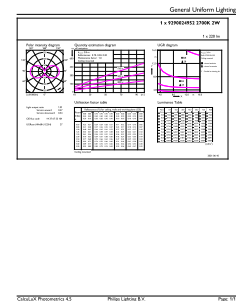

LEDcapsule CorePro 2W G9 827-GUL


CorePro LEDcapsule MV

Photometric data

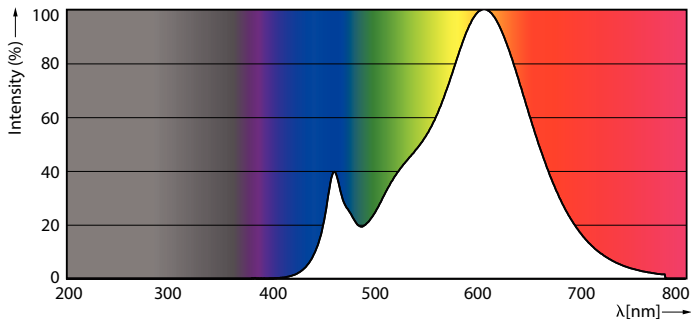


LEDCapsule CorePro 2W G9 827-POC

Lifetime

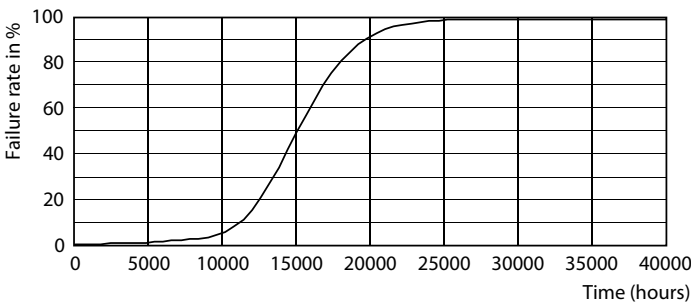

15K LED

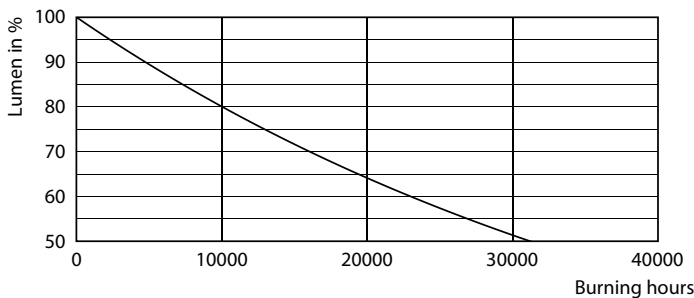

15K LMP

