



MASTER Value Glass LED bulbs

MASTER VLE LEDBulbD3.4-40W E27 927 A60 FR G


Featuring a classic heritage design, Classic filament LED Lamps combine the familiar shapes of incandescent bulbs with the benefits of the long-lasting LED technology. The product offers more energy saving comparing with normal LED bulbs, while in the same time it also provide the custome with good light experience with super dimming performance. MASTER Value Glass Led Bulbs deliver significant energy savings, offering even 30% more compared to normal LED and provides excellent quality of light. By offering a lifetime of 15,000 hours it reduces maintenance costs.

Product data

General Information		LLMF At End Of Nominal Lifetime (Nom) 70 %	
Cap-Base	E27 [E27]		
EU RoHS compliant	Yes		
Nominal Lifetime (Nom)	15000 h		
Switching Cycle	20000X		
Flux measurement reference	Sphere		
Light Technical		Operating and Electrical	
Color Code	927 [CCT of 2700K]	Input Frequency	50 to 60 Hz
Luminous Flux (Nom)	470 lm	Power (Nom)	3.4 W
Color Designation	Warm White (WW)	Lamp Current (Nom)	20 mA
Correlated Color Temperature (Nom)	2700 K	Wattage Equivalent	40 W
Luminous Efficacy (rated) (Nom)	138.00 lm/W	Starting Time (Nom)	0.5 s
Color Consistency	<6	Warm Up Time to 60% Light (Nom)	0.5 s
Color Rendering Index (Nom)	90	Power Factor (Nom)	0.7
		Voltage (Nom)	220-240 V
		Temperature	
		T-Case Maximum (Nom)	80 °C


MASTER Value Glass LED bulbs

Photometric data

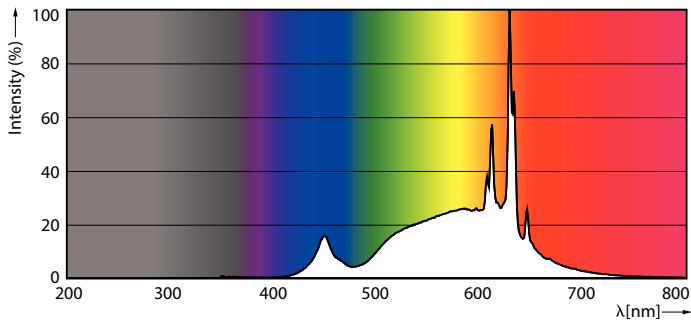


LEDbulb MAS 3,4W A60 E27 927 FR-POC

Lifetime

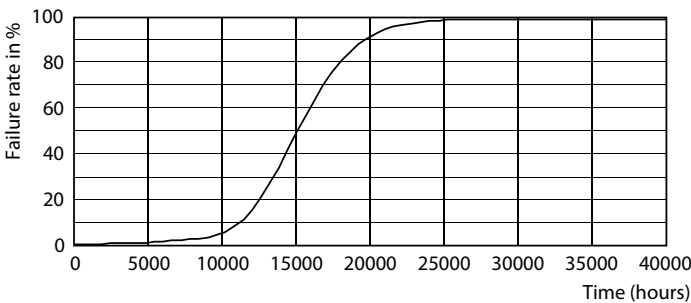

15K LED

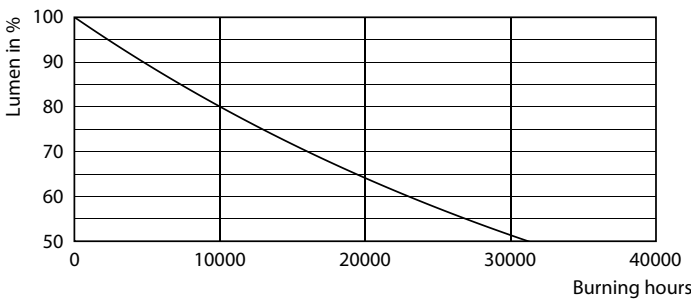

15K LMP

