



MASTER Value Glass LED bulbs

MASTERVLE LEDBulbD5.9-60W B22A60 927FR G UK

Featuring a classic heritage design, Classic filament LED Lamps combine the familiar shapes of incandescent bulbs with the benefits of the long-lasting LED technology. The product offers more energy saving comparing with normal LED bulbs, while in the same time it also provide the custome with good light experience with super dimming performance. MASTER Value Glass Led Bulbs deliver significant energy savings, offering even 30% more compared to normal LED and provides excellent quality of light. By offering a lifetime of 15,000 hours it reduces maintenance costs.

Product data

General Information	
Cap-Base	B22 [B22]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000X
Light Technical	
Color Code	922-927 [CCT of 2200K-2700K]
Luminous Flux (Nom)	806 lm
Color Designation	Warm Glow(WG)
Correlated Color Temperature (Nom)	2200 2700 K
Luminous Efficacy (rated) (Nom)	136.00 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %


Operating and Electrical	
Input Frequency	50 to 60 Hz
Power (Nom)	5.9 W
Lamp Current (Nom)	40 mA
Wattage Equivalent	60 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.6
Voltage (Nom)	220-240 V
Temperature	
T-Case Maximum (Nom)	70 °C
Controls and Dimming	
Dimmable	Yes

MASTER Value Glass LED bulbs

Mechanical and Housing	
Bulb Finish	Frosted
Bulb Shape	A60 [A 60mm]
Approval and Application	
Energy Efficiency Class	D
Energy Consumption kWh/1000 h	6 kWh
EPREL Registration Number	453249
Product Data	
Full product code	871951432479401

Order product name	MASTERVLE LEDBulbD5.9-60W B22A60 927FR G UK
EAN/UPC - Product	8719514324794
Order code	929003010699
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929003010699
Net Weight (Piece)	0.030 kg


Dimensional drawing

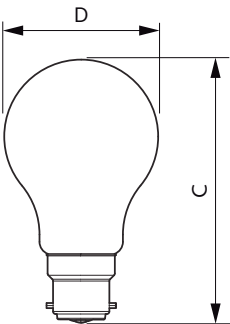


Bulb A60 EU 6-60W 810lm WG B22 FR

Product	D	C
MASTERVLE LEDBulbD5.9-60W B22A60 927FR G UK	60 mm	103 mm

Photometric data

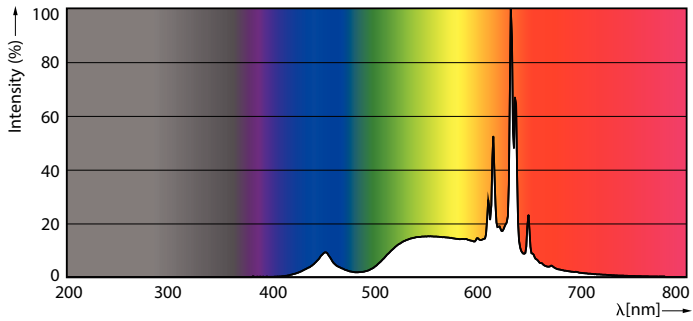


LEDbulb MAS SLR 5,9W A60 E27 927 CL-POC

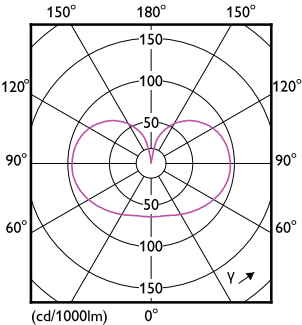

LEDbulb MAS SLR A60 5,9W E27 927 FR-LDD

MASTER Value Glass LED bulbs


Photometric data

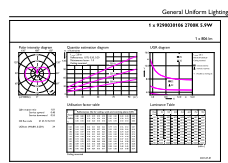


General Photometric Data Page 10

LEDbulb MAS SLR 5,9W A60 B22 927 FR-GUL

Lifetime

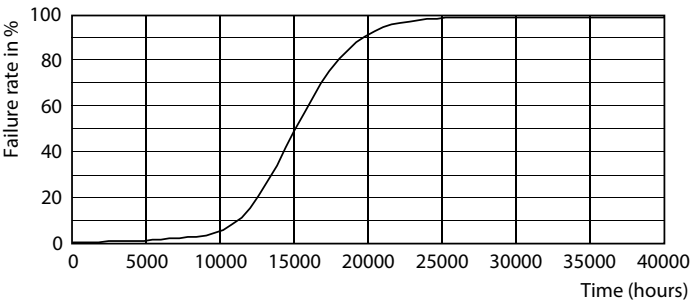

15K LED

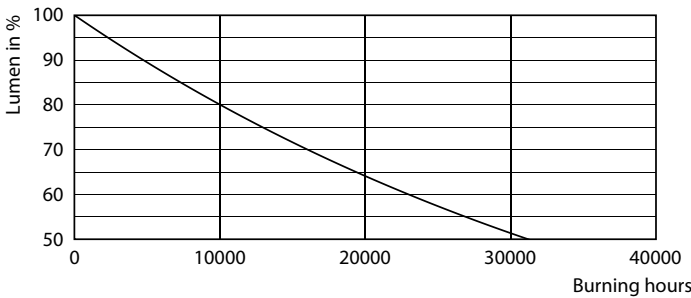

15K LMP

