



CorePro LEDbulb

CoreProLEDbulb ND 13-100W A60 B22 930 UK

LEDbulbs are compatible with existing fixtures with an E27 holder and are designed for retrofit replacement of incandescent bulbs.


Product data

General Information		Voltage (Nom) 220-240 V	
Cap base	B22 [B22]	Temperature	
EU RoHS compliant	Yes	T-Case maximum (nom.) 95 °C	
Nominal lifetime (nom.)	15000 h	Controls and Dimming	
Switching cycle	50,000X	Dimmable No	
Light Technical		Mechanical and Housing	
Colour Code	930 [CCT of 3,000 K]	Lamp Finish Frosted	
Beam Angle (Nom)	200 °	Bulb shape A60 [A 60mm]	
Luminous flux (nom.)	1521 lm	Approval and Application	
Colour designation	White (WH)	Energy Efficiency Class E	
Correlated Colour Temperature (Nom)	3000 K	Energy consumption kWh/1,000 hours 13 kWh	
Luminous efficacy (rated) (nom.)	117.00 lm/W	438127	
Colour consistency	<6	Product Data	
Colour rendering index (nom.)	90	Full product code 871951432978201	
LLMF at end of nominal lifetime (nom.)	70 %	Order product name CoreProLEDbulb ND 13-100W A60 B22 930 UK	
Operating and Electrical		EAN/UPC – product 8719514329782	
Input frequency	50 to 60 Hz	Order code 32978201	
Power (Rated) (Nom)	13 W	SAP numerator – quantity per pack 1	
Lamp current (nom.)	105 mA	Numerator – packs per outer box 10	
Wattage equivalent	100 W	SAP material 929003004099	
Starting time (nom.)	0.5 s		
Warm-up time to 60% light (nom.)	0.5 s		
Power factor (nom.)	0.5		

CorePro LEDbulb

SAP net weight (piece)	0.076 kg
------------------------	----------



Dimensional drawing

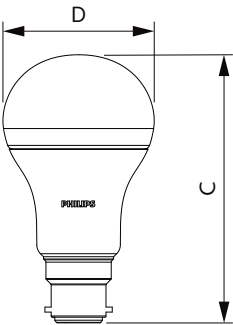

Bulb 220-240V 13-W 152lm 3000K B22 ND

Product	D	C
CoreProLEDbulb ND 13-100W A60 B22 930 UK	60 mm	110 mm


Photometric data

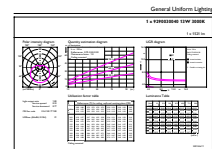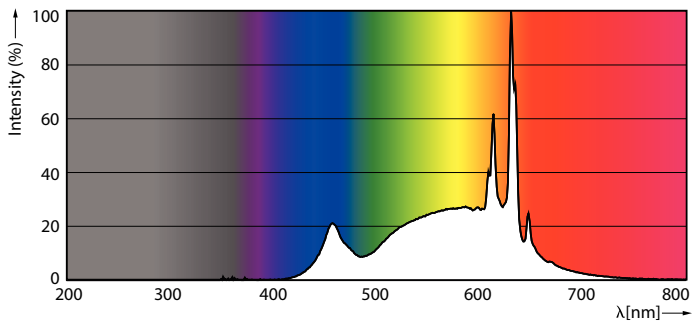

General Information
Photometric data
Page 17

LEDbulb CorePro 7,5W A60 E27 930 FR-POC

LEDbulb CorePro 13W A60 B22 930-GUL

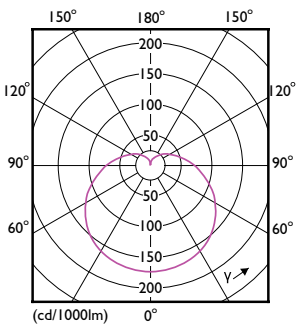


LEDbulb CorePro A60 13W E27 930 FR-LDD

CorePro LEDbulb

Lifetime



15K LED

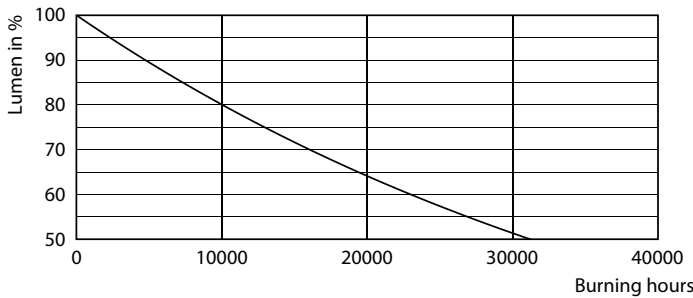

15K LMP

