

CorePro GLASS LED candles and lusters



CorePro LEDCandleND 2-25W B35 B22 827CLG

Featuring a classic heritage design, Classic filament LED Lamps combine the familiar shapes of classic incandescent bulbs with the benefits of the long-lasting LED technology. An very easy choice for people who are looking for the replacement for retrofit LED candles and lusters, as comparing with convential lamps, it provide 90% energy saving. CorePro Glass LED candles and lusters provides excellent quality of light. By offering a lifetime of 15,000 hours it reduces maintenance costs.

Product data


General Information		Power (Nom)	
Cap-Base	B22 [B22]	Lamp Current (Nom)	20 mA
EU RoHS compliant	Yes	Wattage Equivalent	25 W
Nominal Lifetime (Nom)	15000 h	Starting Time (Nom)	0.5 s
Switching Cycle	20000X	Warm Up Time to 60% Light (Nom)	0.5 s
Flux measurement reference	Sphere	Power Factor (Nom)	0.41
Light Technical		Voltage (Nom)	220-240 V
Color Code	827 [CCT of 2700K]	Temperature	
Luminous Flux (Nom)	250 lm	T-Case Maximum (Nom)	36 °C
Color Designation	Warm White (WW)	Controls and Dimming	
Correlated Color Temperature (Nom)	2700 K	Dimmable	No
Luminous Efficacy (rated) (Nom)	125.00 lm/W	Mechanical and Housing	
Color Consistency	<6	Bulb Finish	Clear
Color Rendering Index (Nom)	80	Bulb Shape	B35 [B 35mm]
LLMF At End Of Nominal Lifetime (Nom)	70 %		
Operating and Electrical			
Input Frequency	50 to 60 Hz		

CorePro GLASS LED candles and lusters

Approval and Application	
Energy Efficiency Class	E
Energy Consumption kWh/1000 h	2 kWh
EPREL Registration Number	400292
Product Data	
Full product code	871951434724300
Order product name	CorePro LEDCandleND 2-25W B35 B22 827CLG

EAN/UPC - Product	8719514347243
Order code	929001815692
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929001815692
Net Weight (Piece)	0.012 kg


Dimensional drawing

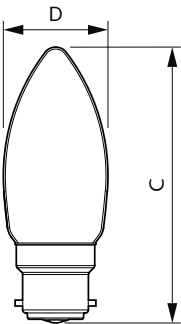


Candle 230V 2-25W 250lm 2700K B22 ND B35

Product	D	C
CorePro LEDCandleND 2-25W B35 B22 827CLG	35 mm	93 mm

Photometric data

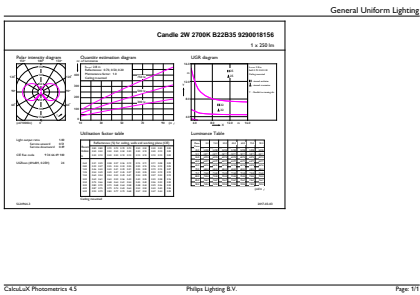


CLA LEDcandle 25W B22 827 CL B35

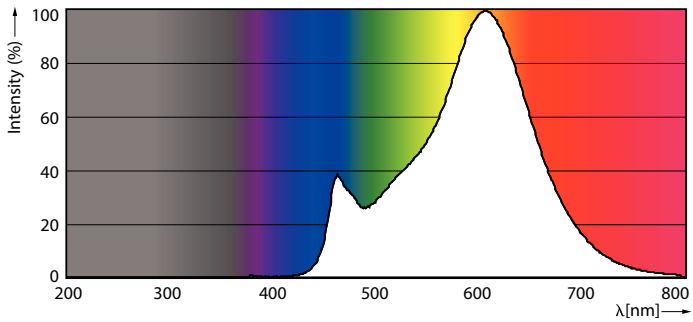

LEDbulb 40W B22 827 CL A60 ND


CorePro GLASS LED candles and lusters

Photometric data

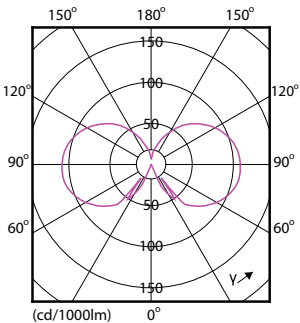


CLA LEDcandle 25W B15 827 CL B35

Lifetime

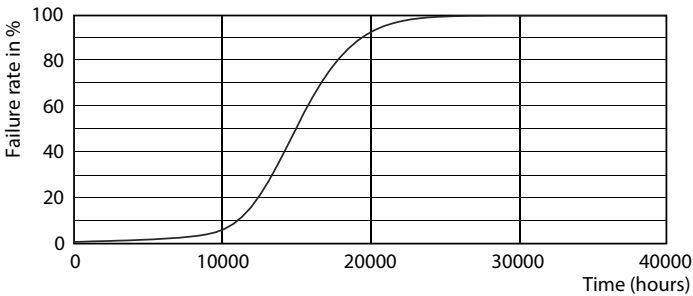

LEDbulb 60W E14 827 FR B38

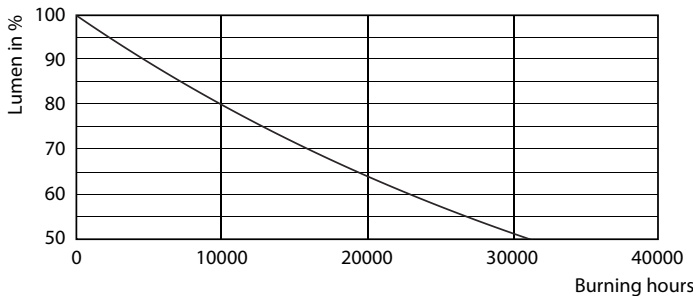

LEDbulb 60W E14 827 FR B38

