



CorePro GLASS LED candles and lusters



CorePro LEDCandleND4.3-40W E14 827B35FRG

Featuring a classic heritage design, Classic filament LED Lamps combine the familiar shapes of classic incandescent bulbs with the benefits of the long-lasting LED technology. An very easy choice for people who are looking for the replacement for retrofit LED candles and lusters, as comparing with convential lamps, it provide 90% energy saving. CorePro Glass LED candles and lusters provides excellent quality of light. By offering a lifetime of 15,000 hours it reduces maintenance costs.

Product data

General Information	
Cap-Base	E14 [E14]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000X
Flux measurement reference	Sphere
Light Technical	
Color Code	827 [CCT of 2700K]
Luminous Flux (Nom)	470 lm
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2700 K
Luminous Efficacy (rated) (Nom)	109.00 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	50 to 60 Hz


Power (Nom)	4.3 W
Lamp Current (Nom)	35 mA
Wattage Equivalent	40 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.5
Voltage (Nom)	220-240 V
Temperature	
T-Case Maximum (Nom)	55 °C
Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Bulb Finish	Frosted
Bulb Shape	B35 [B 35mm]

CorePro GLASS LED candles and lusters

Approval and Application	
Energy Efficiency Class	F
Energy Consumption kWh/1000 h	5 kWh
EPREL Registration Number	387382
Product Data	
Full product code	871951434718200
Order product name	CorePro LEDCandleND4.3-40W E14 827B35FRG

EAN/UPC - Product	8719514347182
Order code	929001345392
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929001345392
Net Weight (Piece)	0.012 kg


Dimensional drawing

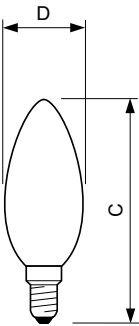


Candle B35 230V 4-40W 250lm 2700K E14ND

Product	D	C
CorePro LEDCandleND4.3-40W E14 827B35FRG	35 mm	97 mm

 Photometric data




LEDbulb, Bulb A21 14W, 18W 2200-2700K

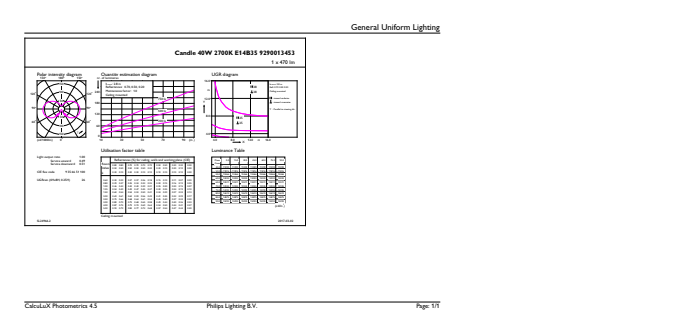

LEDbulb 40W E14 827 FR B35


CorePro GLASS LED candles and lusters

Photometric data

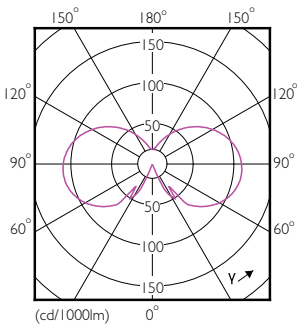


LEDbulb 40W E14 827 FR B35

Lifetime

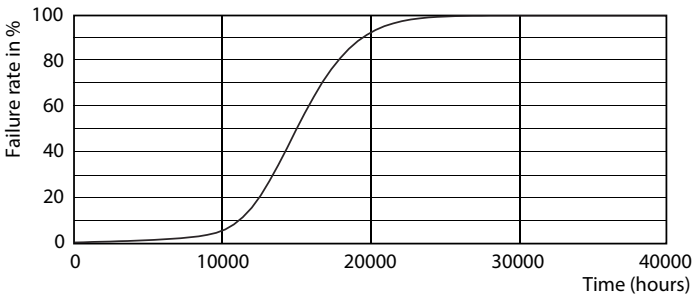

LEDbulb 40W E14 827 FR B35

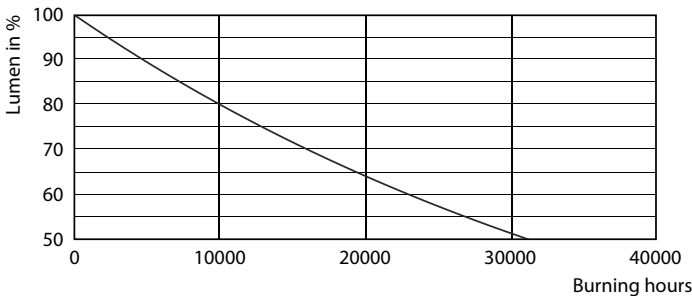

LEDbulb 25W E14 827 FR B35

