



# CorePro GLASS LED candles and lustres



## CorePro LEDCandleND6.5-60W B35 E14827FRG

Featuring a classic heritage design, Classic filament LED lamps combine the familiar shapes of classic incandescent bulbs with the benefits of the long-lasting LED technology. An very easy choice for people who are looking for the replacement for retrofit LED candles and lustres: compared to convential lamps, it provides a 90% energy saving. CorePro Glass LED candles and lustres provide excellent quality of light. By offering a lifetime of 15,000 hours, they reduce maintenance costs.

### Product data

General Information	
Cap base	E14 [ E14]
EU RoHS compliant	Yes
Nominal lifetime (nom.)	15000 h
Switching cycle	20,000X
	Sphere
Light Technical	
Colour Code	827 [ CCT of 2,700 K]
Luminous flux (nom.)	806 lm
Colour designation	Warm white (WW)
Correlated Colour Temperature (Nom)	2700 K
Luminous efficacy (rated) (nom.)	124.00 lm/W
Colour consistency	<6
Colour rendering index (nom.)	80
LLMF at end of nominal lifetime (nom.)	70 %
Operating and Electrical	
Input frequency	50 to 60 Hz


Power (Rated) (Nom)	6.5 W
Lamp current (nom.)	50 mA
Wattage equivalent	60 W
Starting time (nom.)	0.5 s
Warm-up time to 60% light (nom.)	0.5 s
Power factor (nom.)	0.55
Voltage (Nom)	220-240 V
Temperature	
T-Case maximum (nom.)	55 °C
Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Lamp Finish	Frosted
Bulb shape	B35 [ B 35mm]

CorePro GLASS LED candles and lustres

Approval and Application	
Energy Efficiency Class	E
Energy consumption kWh/1,000 hours	7 kWh
	387443
Product Data	
Full product code	871951434750200
Order product name	CorePro LEDCandleND6.5-60W B35 E14827FRG

EAN/UPC – product	8719514347502
Order code	34750200
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
SAP material	929002028292
SAP net weight (piece)	0.012 kg


Dimensional drawing

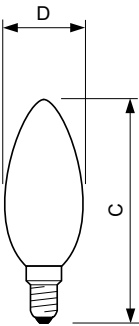


Candle B35 60W 806lm 2700K E14 NDFrosted

Product	D	C
CorePro LEDCandleND6.5-60W B35 E14827FRG	35 mm	97 mm


Photometric data

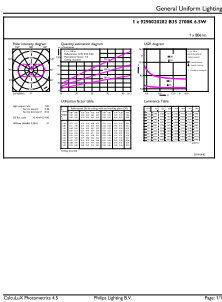

LEDcandle E14 B35 827 FR

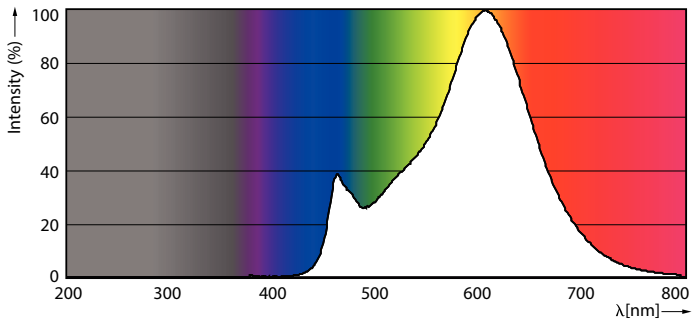


LEDbulb 6,5-60W E14 B35

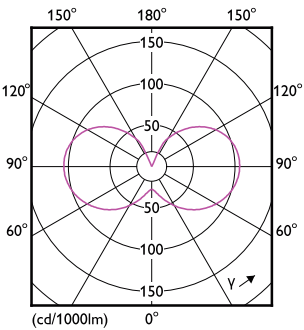


LEDbulb 6,5-60W E14 P45

CorePro GLASS LED candles and lustres

Lifetime

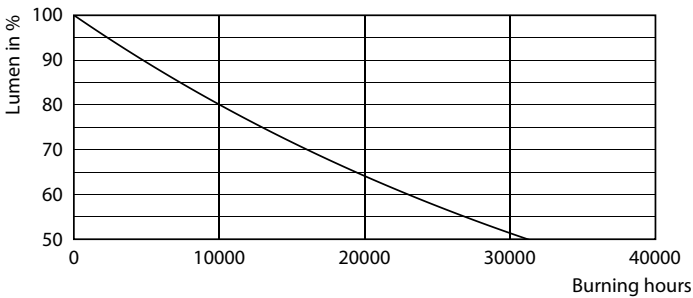

LEDbulb 6,5-60W E14 B35

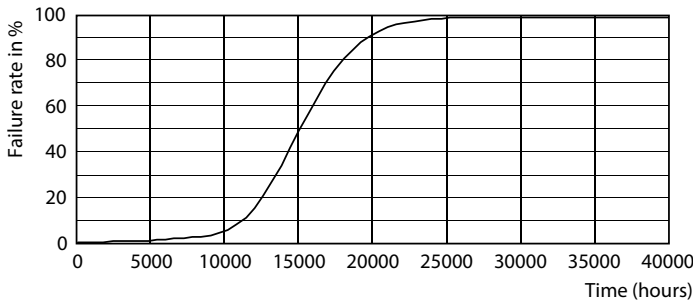

LEDbulb 6,5-60W E14 B35

