



CorePro GLASS LED candles and lusters



CorePro LEDLusterND6.5-60W P45 E14827FRG

Featuring a classic heritage design, Classic filament LED Lamps combine the familiar shapes of classic incandescent bulbs with the benefits of the long-lasting LED technology. An very easy choice for people who are looking for the replacement for retrofit LED candles and lusters, as comparing with convential lamps, it provide 90% energy saving. CorePro Glass LED candles and lusters provides excellent quality of light. By offering a lifetime of 15,000 hours it reduces maintenance costs.

Product data


General Information		Power (Nom)	
Cap-Base	E14 [E14]	Lamp Current (Nom)	50 mA
EU RoHS compliant	Yes	Wattage Equivalent	60 W
Nominal Lifetime (Nom)	15000 h	Starting Time (Nom)	0.5 s
Switching Cycle	20000X	Warm Up Time to 60% Light (Nom)	0.5 s
Flux measurement reference	Sphere	Power Factor (Nom)	0.55
Light Technical		Voltage (Nom)	220-240 V
Color Code	827 [CCT of 2700K]	Temperature	
Luminous Flux (Nom)	806 lm	T-Case Maximum (Nom)	55 °C
Color Designation	Warm White (WW)	Controls and Dimming	
Correlated Color Temperature (Nom)	2700 K	Dimmable	No
Luminous Efficacy (rated) (Nom)	124.00 lm/W	Mechanical and Housing	
Color Consistency	<6	Bulb Finish	Frosted
Color Rendering Index (Nom)	80	Bulb Shape	P45 [P 45mm]
LLMF At End Of Nominal Lifetime (Nom)	70 %		
Operating and Electrical			
Input Frequency	50 to 60 Hz		

CorePro GLASS LED candles and lusters

Approval and Application	
Energy Efficiency Class	E
Energy Consumption kWh/1000 h	7 kWh
EPREL Registration Number	387448
Product Data	
Full product code	871951434760100
Order product name	CorePro LEDLusterND6.5-60W P45 E14827FRG

EAN/UPC - Product	8719514347601
Order code	929002028792
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929002028792
Net Weight (Piece)	0.014 kg


Dimensional drawing

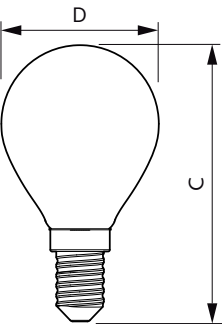


Candle P45 60W 806lm 2700K E14 NDFrosted

Product	D	C
CorePro LEDLusterND6.5-60W P45 E14827FRG	45 mm	80 mm

Photometric data

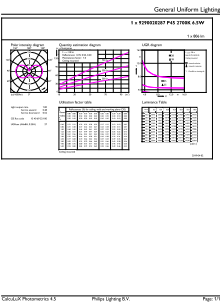


LEDluster E14 P45 827 FR

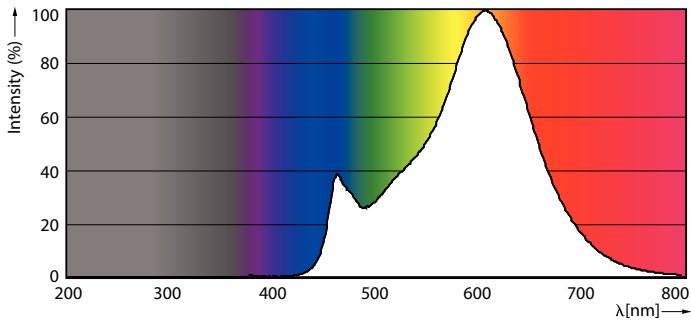

LEDbulb 6,5-60W E14 B35


CorePro GLASS LED candles and lusters

Photometric data

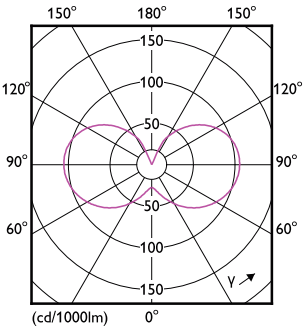


LEDbulb 6,5-60W E14 P45

Lifetime

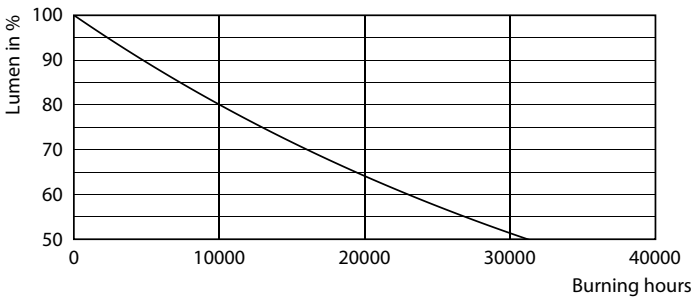

LEDbulb 6,5-60W E14 B35

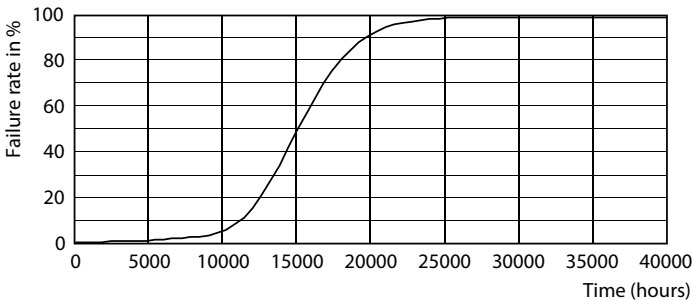

LEDbulb 6,5-60W E14 B35

