



MASTER LEDtube Mains T5



MASTER LEDtube 1200mm HE 16.5W 830 T5 EU

The new Philips Master LEDtube Mains T5 brings simplicity to your lighting project. You don't need to pay attention to the driver technology anymore. Thanks to a unique design, Philips MASTER LEDtube Mains T5 installs in luminaires operating on mains power connection. So simple to operate! Perfectly safe, reliable & easy to install, the Philips MASTER LEDtube Mains T5 is the ideal alternative to standard fluorescent tubes to maximise value over lifetime with high energy savings and lower maintenance costs.

Product data


General Information		Operating and Electrical	
Cap base	G5 [G5]	Input frequency	50 to 60 Hz
EU RoHS compliant	Yes	Power (Rated) (Nom)	16.5 W
Nominal lifetime (nom.)	50000 h	Lamp current (nom.)	85 mA
Switching cycle	200,000X	Starting time (nom.)	0.5 s
	Sphere	Warm-up time to 60% light (nom.)	0.5 s
		Power factor (nom.)	0.92
		Voltage (Nom)	220-240 V
Light Technical		Temperature	
Colour Code	830 [CCT of 3,000 K]	T-ambient (max.)	45 °C
Beam Angle (Nom)	200 °	T-ambient (min.)	-20 °C
Luminous flux (nom.)	2300 lm	T storage (max.)	65 °C
Colour designation	White (WH)	T storage (min.)	-40 °C
Correlated Colour Temperature (Nom)	3000 K	T-Case maximum (nom.)	70 °C
Luminous efficacy (rated) (nom.)	139.00 lm/W		
Colour consistency	<6		
Colour rendering index (nom.)	80		
LLMF at end of nominal lifetime (nom.)	70 %		

MASTER LEDtube Mains T5

Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Lamp Finish	Frosted
Bulb material	Glass
Product length	1200 mm
Bulb shape	Tube, double-ended
Approval and Application	
Energy Efficiency Class	D
Energy-saving product	Yes
Approval marks	RoHS compliance CE marking KEMA Keur certificate

Energy consumption kWh/1,000 hours	17 kWh
	467300
Product Data	
Full product code	871951433431100
Order product name	MASTER LEDtube 1200mm HE 16.5W 830 T5 EU
EAN/UPC – product	8719514334311
Order code	33431100
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
SAP material	929003044402
SAP net weight (piece)	0.215 kg


Dimensional drawing

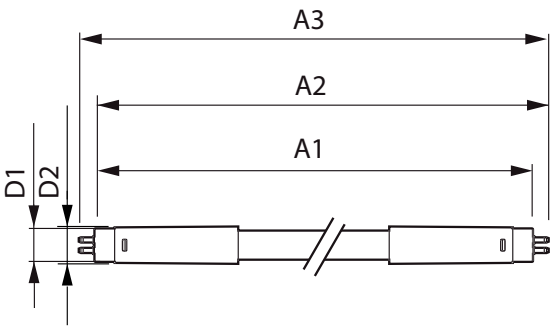


MAS LEDtube 1200mm HE 16.5W 830 T5

Product
MASTER LEDtube 1200mm HE 16.5W 830 T5 EU

Photometric data

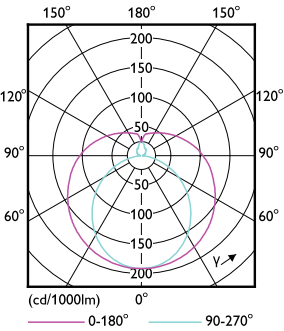


LEDtube MAS 8W G5 1000lm

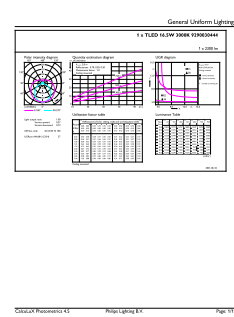

LEDtube MAS G3 16,5W G13 2300lm 830-GUL


MASTER LEDtube Mains T5

Photometric data

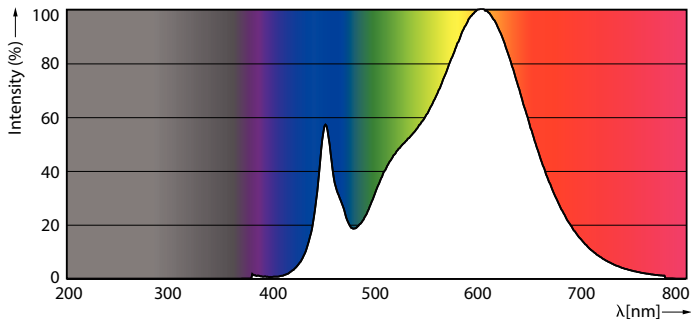


LEDtube MAS G3 16,5W G13 2300lm 830-POC


Lifetime

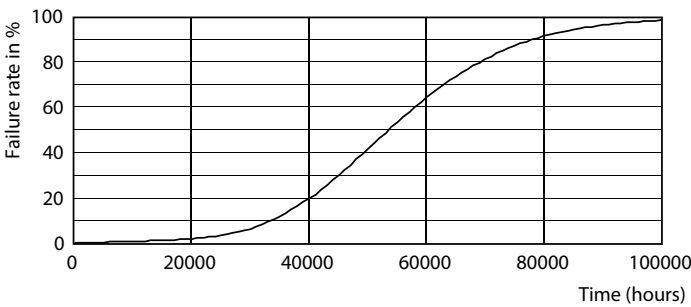


LEDtube 50K-LED

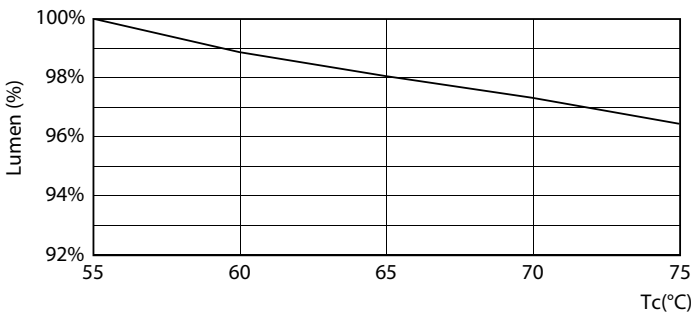

LEDtube MAS G3 8W 50K LumenVsTc-LMP

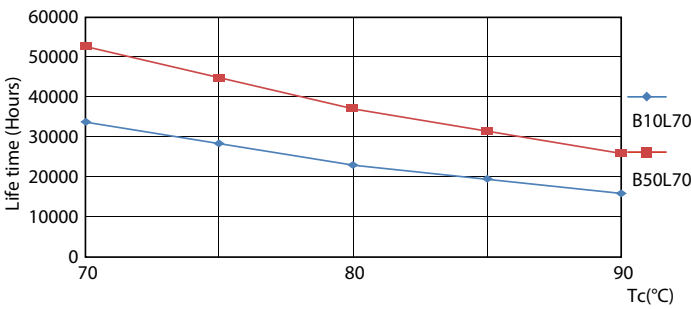


LEDtube MAS 1 26W 50K LifetimeVsTc-LED

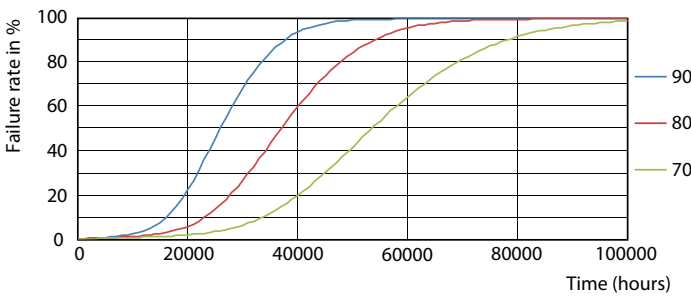

LEDtube MAS 1 26W 50K FailureRate-LED

MASTER LEDtube Mains T5

Lifetime

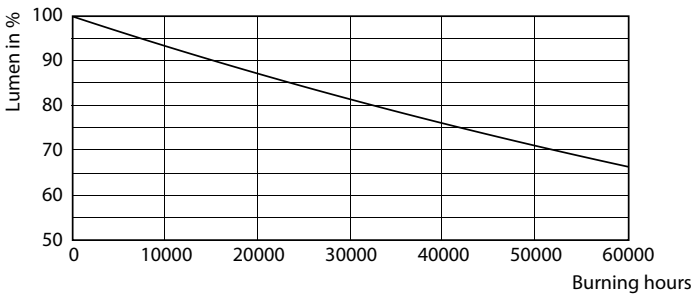

LEDtube 50K-LMP

