


TSC 02 Fibre patch cord 2m SC

Art. Number 307011

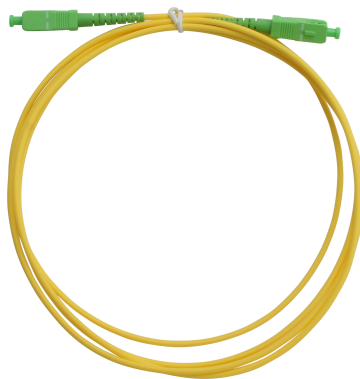

Fibre Optic patch cord

The **TSC xx patch cord** is a single mode cable terminated with SC/APC connector plugs at both ends. It is recommended for indoor installations in cable ducts and cabinets of fibre optic networks used for applications like:

- CATV distribution and DOSIS data transmission
- SAT-IF and DTT distribution
- Other fibre optic communication systems

Technical Specifications

ORDER INFORMATION

EAN Number 5702663070110

OPTICAL CHARACTERISTICS

Fibre type G.652.D
 Optical Attenuation 1310/1550 | dB/km 0.3 dB/km
 Optical cable type Single-mode

CONSTRUCTION

Jacket – dimension | mm 3.0 mm
 Jacket - material LSZH

CHARACTERISTICS

Wavelength | nm 1310...1550 nm

RETURN LOSS

Return Loss | dB >60 dB

OPERATIONAL

Temperature - operating | °C -40...+80 °C

CONNECTORS

Connector Type Optical - SC/APC



TRIAx

connecting the future

Technical Specifications

MECHANICAL

Cable length m	2 m
Colour	Yellow
Packaging Depth m	0.000 m
Packaging Height m	0.000 m
Total Weight kg	0.021 kg
Packaging Width m	0.000 m
Minimum bending radius mm	50 mm
Net Weight kg	0.019 kg
Tara Weight kg	0.002 kg
Packaging Volume m3	0.000 m3