

TIME LED®

URBAN WHITE LED 14.5W ROUND BULKHEAD WITH MICROWAVE SENSOR

SPECIFICATION SHEET

PRODUCT CODE: 780671

BULK
HEAD

14.5W
=116W

1300
LUMENS

IP65



BULKHEAD



116W
EQUIVALENT



1300
LUMENS



120°
BEAM
ANGLE



NON-DIMMABLE



25,000 HOURS
LIFESPAN



3 YEARS
WARRANTY




ENERGY
RATING

SPECIFICATION

Product code	780671
Fitting	Bulkhead
Bulb shape	SMD
Wattage	14.5W
Equivalent wattage	116W
Lumens	1300lm
Driver included	Yes
Dimmable	No
Beam Angle	120°
Diameter	Ø283mm
Depth	82mm
Weight	0.8kg
Lifespan	25,000 Hours
Warranty	3 Years
Energy consumption	14.5kWh/1000h
Input frequency	50Hz
Voltage	220-240V
Energy rating	A+
Material	Mixed PC
Packaging	White Box + Colour Sticker
IP Rating	IP65

OPTICAL TEST PARAMETERS

Voltage	220-240V
Current	0.07A
Power	15W
CCT	No
Ra	80
Lumens	1260lm
Lumens per watt	89lm/W
Colour tolerance	<5
Power factor	0.8
Hertz	50/60Hz

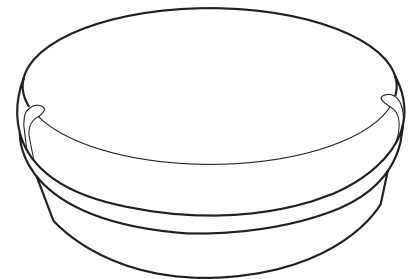


4000K
COOL WHITE

COLOUR TEMPERATURE



220-240V

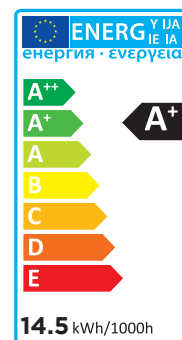

TIME LED is part of Pitacs Limited

Bradbourne Point, Bradbourne Drive, Tilbrook, Milton Keynes, Buckinghamshire MK7 8AT

T: +44 (0)1908 271155 F: +44 (0)1908 640017 E: info@timeled.co.uk W: www.timeled.co.uk



SPEC_780671_V1_JULY2020