



AB-PB-1014 PUSH BUTTON SWITCH, 12V LED, GREEN ILLUMINATED

SWITCHES

Specifications

Rating	12VDC 10A
Colour	Black Housing, Green Illuminated
Switch Action	ON-OFF DPST 4P with Lamp 12V
Lamp	LED
Contact resistance	30m Ohms max
Insulation resistance	DC500V 100m Ohms min
Withstand voltage	AC1500V 1 minute
Electrical life	1000 cycles at full load
Operation force	1000-1400gf
Operating temperature	-25°C~+125°C
IP Rating	IP40

AB-PB-1014

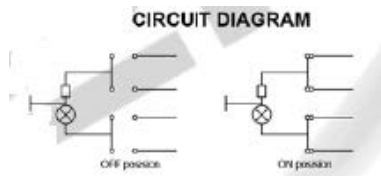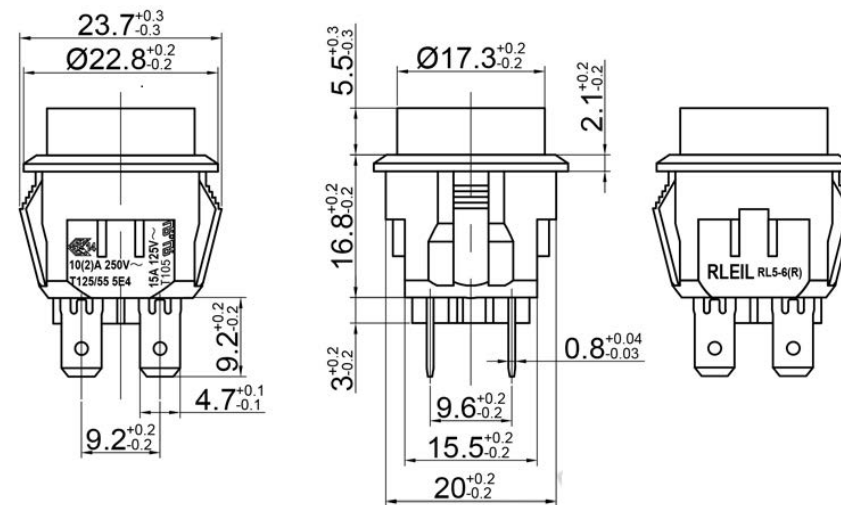


Approvals




Example image

Cut out (mm)

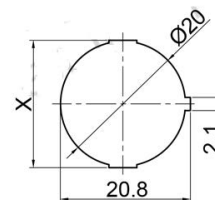

Terminals

 

Materials

- Housing: Nylon #66 UL 94V-2
- Button: Nylon #66 UL 94V-2
- Terminal: Copper alloy Ag plated
- Contat: AgSnO₂In₂O₄(10)/Cu