

Specifications**ABI-009-RC**

Rated voltage	6VDC
Operating voltage	4~8VDC
Rated current*	≤30mA
Sound output at 10cm*	≥85dB
Resonant frequency	2300±300Hz
Tone	Continuous
Operating temperature	-25~+80°C
Storage temperature	-30~+85°C
Weight	2g

*Value applying at rated voltage (DC)


Features

- ROHS compliant
- Black in colour
- With internal drive circuit
- Sealed structure
- Wave solderable and washable
- Housing material: Noryl

All data at 25°C unless otherwise specified

Applications

- Computer and peripherals
- Communications equipment
- Portable equipment
- Automobile electronics
- POS system
- Electronic cash register

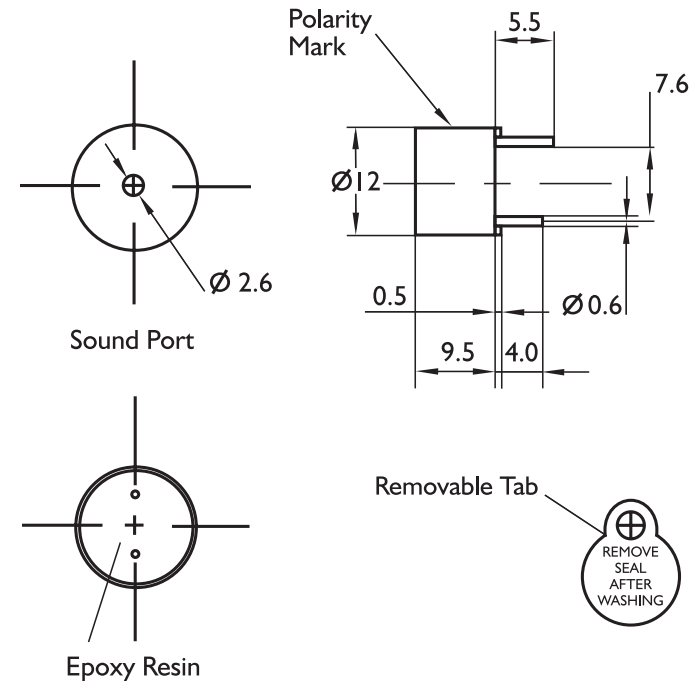

Dimensions Unit: mm Tolerance: ±0.5mm



ALAN BUTCHER COMPONENTS LTD

Alan Butcher Components Ltd

Unit 1 Beechwood Clump Farm Industrial Estate Tin Pot Lane Blandford Dorset DT11 7TD

Telephone 01258 456360 Facsimile 01258 459194 Email sales@abcomponents.co.uk

www.abcomponents.co.uk