

Specifications

ABT-414-RC


Rated voltage (Vp-p square wave)	5Vp-p
Operating voltage	3~8Vp-p
Rated current at rated voltage	≤40mA
Sound output at 2400Hz at 10cm	≥85dB
Resonant frequency	2400Hz
Coil resistance	47±5Ω
Operating temperature	-20~+75°C
Storage temperature	-30~+85°C
Weight	2g

Requires additional electronic circuitry to operate as a sounder

Features

- ROHS compliant
- Wave solderable and washable
- Sealed base
- Housing material: Noryl

All data at 25°C unless otherwise specified

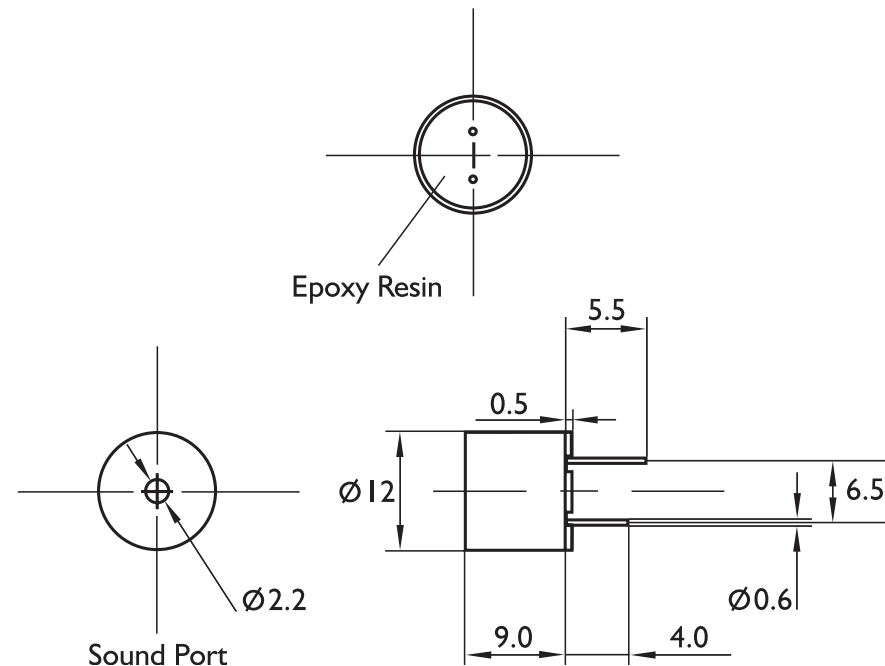

Dimensions Unit: mm Tolerance: ±0.5mm



ALAN BUTCHER COMPONENTS LTD

Alan Butcher Components Ltd

Unit 1 Beechwood Clump Farm Industrial Estate Tin Pot Lane Blandford Dorset DT11 7TD

Telephone 01258 456360 Facsimile 01258 459194 Email sales@abcomponents.co.uk

www.abcomponents.co.uk