


BU-122730291

(4 Position Female Receptacle Cable Assembly to Wire ends, 4.92')

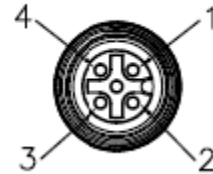

J1	COLOR	J2
1	BROWN	OPEN
2	WHITE	
3	BLUE	
4	BLACK	

- Mueller's BU-122730291 is a 4 Position Female Receptacle Cable Assembly to free wire ends.
- Shell size for connector: M12 x 1.0 (A Coding)
- Cable Material: 4 Conductor, 22AWG, PVC
 - Overall length = 4.92' (1.5m)
- Coupling Nut: Anodized Aluminum
- Rating:
 - Voltage: 250V AC/DC
 - Current: 4 Amps
 - Standard: IEC 61076-2-101
 - Waterproof: IP67/IP68
 - Temperature: -40°C to 105°C
- RoHS 3 Compliant