

OUTDOOR DECORATIVE WALL LIGHT WAVE IP65 310LM 7W 3000K UP/DOWN LIGHT DARK GREY INTEGRAL

ILDEA011



Discover Integral's new outdoor range. Light up the exterior of your home with these compact, stylish and contemporary LED luminaires. Weatherproof and hard-wearing, this range is designed to last against the elements while bringing a designer look to your surroundings. The Wave's linear up/down design brings a modern feel to your outdoor areas. Constructed with a polycarbonate diffuser so you are left with a soft, even glow.

Details

Quick Order Code:	296172
Barcode:	5055788232445
Category:	Luminaires
Range Name:	Wall Light
Product Type:	Outdoor
Market Segment:	Residential Outdoor
Warranty (Years):	3
CE RoHS:	Yes

Physical Data

Product Length (mm):	230
Product Depth (mm):	58
Product Width (mm):	72
Product Weight (g):	400
Optic:	Opal Polycarbonate diffuser
Material:	Die cast aluminium body with powder coated finish
Luminaire Fixing:	Wall Mounted
Placement / Application:	Outdoor, General Lighting

Electrical Data

Power Consumption (w):	7
Power Factor:	0.8
Amperage (mA):	300
Dimming:	Non-Dimmable
Driver Included:	Yes
Electric Current:	AC


EN:	EN-60598
LVD Certified:	Yes

Light Data

Luminous Flux in Lumens (lm):	310
Luminous efficacy (lm/W):	44
Correlated Colour Temperature (CCT) (K):	3000
Colour Temperature Name:	Warm White
Colour Rendering Index (CRI):	80
Instant on (Less than 1 second):	Yes
LED Type:	Surface mounted device (SMD)
Lifetime (hours):	25000
Switching Cycles:	12500

Environment

EN:	EN-60598
LVD Certified:	Yes
CE RoHS:	Yes
EU Luminaire:	L
Hg 0% (Mercury Free):	Yes
IP Rating (Ingress Protection):	IP65
Lowest Operating Temperature (°C):	-20
Maximum Operating Temperature (°C):	65

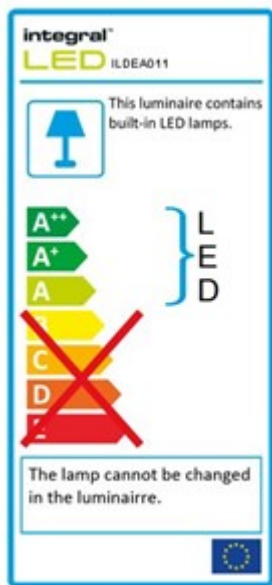

Packaging

Package Weight (g):	450
Package Length (mm):	240
Package Width (mm):	85
Package Depth (mm):	70

Portal.integral-led.com