

**OUTDOOR DECORATIVE WALL LIGHT PATHLUX STEP IP65 100LM 2.2W  
3000K DOWN LIGHT WHITE INTEGRAL**

ILBLA020



Discover Integral's new outdoor range. Light up the exterior of your home with these compact, stylish and contemporary LED luminaires. Weatherproof and hard-wearing, this range is designed to last against the elements while bringing a designer look to your surroundings. Gently illuminate your pathways with the stylish and hardwearing Pathlux. This Step model features a circular design in white.

**Details**

<b>Quick Order Code:</b>	275262
<b>Barcode:</b>	5055788232889
<b>Category:</b>	Luminaires
<b>Range Name:</b>	Wall Light
<b>Product Type:</b>	Outdoor
<b>Market Segment:</b>	Residential Outdoor
<b>Warranty (Years):</b>	3
<b>CE RoHS:</b>	Yes

**Physical Data**

<b>Product Depth (mm):</b>	30
<b>Product Weight (g):</b>	163
<b>Optic:</b>	Clear Polycarbonate diffuser
<b>Material:</b>	Polycarbonate body
<b>Luminaire Fixing:</b>	Wall Mounted
<b>Placement / Application:</b>	Outdoor, General Lighting

**Electrical Data**


<b>Power Consumption (w):</b>	2.2
<b>Power Factor:</b>	0.3
<b>Dimming:</b>	Non-Dimmable
<b>Driver Included:</b>	Yes
<b>Electric Current:</b>	AC
<b>EN:</b>	EN-60598
<b>LVD Certified:</b>	Yes

**Light Data**

Luminous Flux in Lumens (lm):	100
Luminous efficacy (lm/W):	45
Correlated Colour Temperature (CCT) (K):	3000
Colour Temperature Name:	Warm White
Colour Rendering Index (CRI):	80
Instant on (Less than 1 second):	Yes
LED Type:	Surface mounted device (SMD)
Lifetime (hours):	25000
Switching Cycles:	12500

## Environment

EN:	EN-60598
LVD Certified:	Yes
CE RoHS:	Yes
EU Luminaire:	L
Hg 0% (Mercury Free):	Yes
IP Rating (Ingress Protection):	IP65
Lowest Operating Temperature (°C):	-20
Maximum Operating Temperature (°C):	60

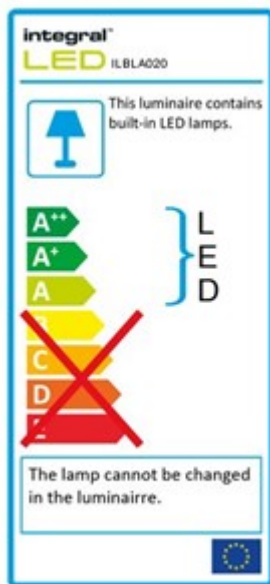

## Packaging

Package Length (mm):	135
Package Width (mm):	40
Package Depth (mm):	110

[Portal.integral-led.com](http://Portal.integral-led.com)