

OUTDOOR DECORATIVE WALL LIGHT GEOLUX IP65 620LM 13W 4000K OMNI DIRECTIONAL DARK GREY INTEGRAL

ILDEA021



The Integral LED Outdoor range offers style and substance, with contemporary designs and hardwearing, weatherproof aluminium construction. This range of modern luminaires creates the perfect accent lighting for exterior walls in residential and commercial environments with all the low-energy and long-life benefits of LED. The Geolux is an attractive elliptical wall light with a polycarbonate diffuser that gives a gentle wash of light to your wall. The dark grey, powder coated finish is both beautiful and rugged.

Details

Quick Order Code:	529510
Barcode:	5055788233176
Category:	Luminaires
Range Name:	Wall Light
Product Type:	Outdoor
Market Segment:	Residential Outdoor
Warranty (Years):	3
CE RoHS:	Yes

Physical Data

Product Length (mm):	169
Product Depth (mm):	55
Product Width (mm):	219
Product Weight (g):	700
Optic:	Polycarbonate diffuser
Material:	Die cast aluminium body with powder coated finish
Luminaire Fixing:	Wall Mounted
Placement / Application:	Outdoor, General Lighting

Electrical Data

Power Consumption (w):	13
Power Factor:	0.8
Amperage (mA):	300
Dimming:	Non-Dimmable
Driver Included:	Yes
Electric Current:	AC


EN:	EN-60598
LVD Certified:	Yes

Light Data

Luminous Flux in Lumens (lm):	620
Luminous efficacy (lm/W):	48
Correlated Colour Temperature (CCT) (K):	4000
Colour Temperature Name:	Cool White
Beam Angle:	120
Colour Rendering Index (CRI):	80
Instant on (Less than 1 second):	Yes
LED Type:	Surface mounted device (SMD)
Lifetime (hours):	25000
Switching Cycles:	12500

Environment

EN:	EN-60598
LVD Certified:	Yes
CE RoHS:	Yes
EU Luminaire:	L
Hg 0% (Mercury Free):	Yes
IP Rating (Ingress Protection):	IP65
Lowest Operating Temperature (°C):	-20
Maximum Operating Temperature (°C):	65

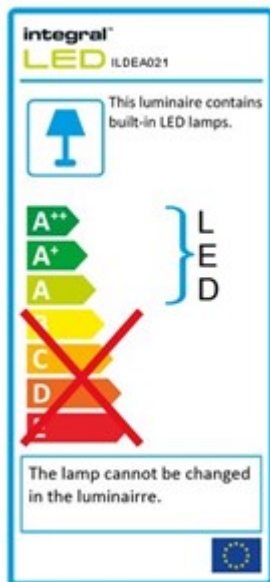

Packaging

Package Weight (g):	850
Package Length (mm):	180
Package Width (mm):	230
Package Depth (mm):	65

Portal.integral-led.com