

**OUTDOOR DECORATIVE WALL LIGHT VISTALUX IP65 420LM 9W 4000K
UP/DOWN LIGHT DARK GREY INTEGRAL**

ILDEA023



The Integral LED Outdoor range offers style and substance, with contemporary designs and hardwearing, weatherproof aluminium construction. This range of modern luminaires creates the perfect accent lighting for exterior walls in residential and commercial environments with all the low-energy and long-life benefits of LED. The Wave is an attractive up/down wall light with a polycarbonate diffuser that gives a gentle wash of light to your wall. The dark grey, powder coated finish is both beautiful and rugged.

Details

Quick Order Code:	529642
Barcode:	5055788233213
Category:	Luminaires
Range Name:	Wall Light
Product Type:	Outdoor
Market Segment:	Residential Outdoor
Warranty (Years):	3
CE RoHS:	Yes

Physical Data

Product Length (mm):	236
Product Depth (mm):	68
Product Width (mm):	75
Product Weight (g):	550
Optic:	Polycarbonate diffuser
Material:	Die cast aluminium body with powder coated finish
Luminaire Fixing:	Wall Mounted
Placement / Application:	Outdoor, General Lighting

Electrical Data

Power Consumption (w):	9
Power Factor:	0.8
Amperage (mA):	300
Dimming:	Non-Dimmable
Driver Included:	Yes
Electric Current:	AC


EN:	EN-60598
LVD Certified:	Yes

Light Data

Luminous Flux in Lumens (lm):	420
Luminous efficacy (lm/W):	47
Correlated Colour Temperature (CCT) (K):	4000
Colour Temperature Name:	Cool White
Beam Angle:	100
Colour Rendering Index (CRI):	80
Instant on (Less than 1 second):	Yes
LED Type:	Surface mounted device (SMD)
Lifetime (hours):	25000
Switching Cycles:	12500

Environment

EN:	EN-60598
LVD Certified:	Yes
CE RoHS:	Yes
EU Luminaire:	L
Hg 0% (Mercury Free):	Yes
IP Rating (Ingress Protection):	IP65
Lowest Operating Temperature (°C):	-20
Maximum Operating Temperature (°C):	65

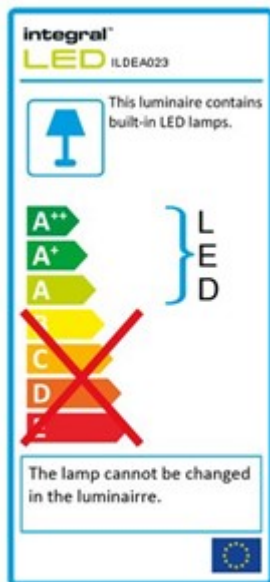

Packaging

Package Weight (g):	600
Package Length (mm):	250
Package Width (mm):	80
Package Depth (mm):	85

Portal.integral-led.com