

TIME LED®

SPECIFICATION SHEET

PRODUCT CODE: 790212

Our latest Premium Multi Beam Angle LED Highbays are a compact design and an ideal replacement for traditional highbay fixtures. You can change the beam angle between 70, 85 and 105 degrees simply by rotation and are supplied as standard with driver and made out of high-quality durable material, making them extremely sturdy. Ideal area lighting for interior and exterior applications: Warehouses & factories, airports, exhibition halls, stadiums and more.

ELEMENTS 240W PREMIUM MULTI BEAM ANGLE HIGHBAY

HIGH-
BAY

240W
=450W

36,000
LUMENS

IP65



450W
EQUIVALENT



36,000
LUMENS



70°
85°
105°
BEAM
ANGLE



NON-DIMMABLE



50,000 HOURS
LIFESPAN







5 YEARS
WARRANTY

SPECIFICATION

Product Code	790212
Type	Highbay
Lamp Type	SMD 2835
Wattage	240W
Equivalent Wattage	450W
Lumens	36,000lm
Driver Included	Yes
Dimmable	No
Beam Angle	Switchable Lens 3 in 1: 105°/85°/70°
Diameter	Ø441mm
Height	212mm (Including hook)
Weight	5.15kg
Cable Length	2m
Lifespan	50,000 Hours
Warranty	5 Years
Energy Consumption	240kWh/1000h
Material	Aluminium + PC
Packaging	Brown Box + Black Print
IP Rating	IP65

Voltage	100-277V
CCT	6000K
Ra	80
Power factor	0.9
Input Frequency	50Hz
Current (A)	1.045A (under 105° testing)
Colour Tolerance	<6
Energy Rating	A+

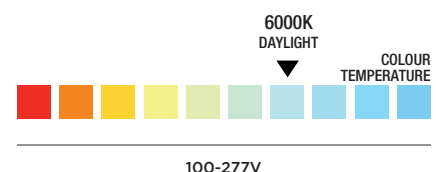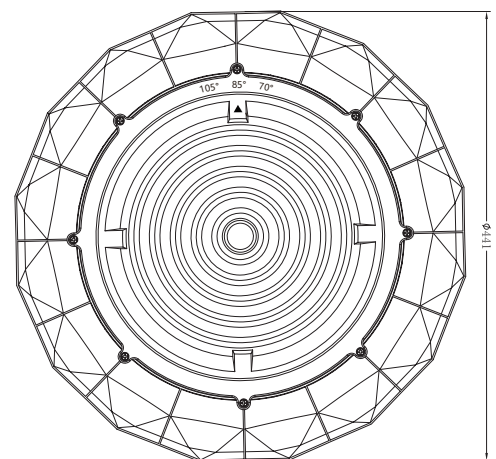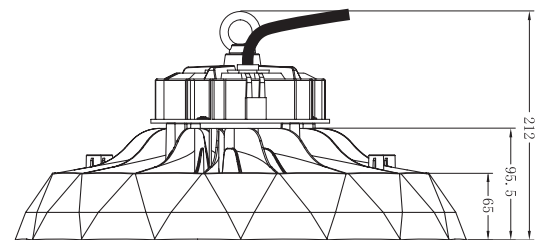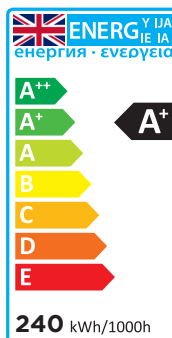

TIME LED is the Lighting Division of Pitacs Limited

Bradbourne Point, Bradbourne Drive, Tilbrook, Milton Keynes, Buckinghamshire MK7 8AT

T: +44 (0)1908 271155 F: +44 (0)1908 640017 E: info@timeled.co.uk W: www.timeled.co.uk



SPEC_790212_V3_AUG2021