

2970 Series T-style Handheld Enclosure


Product overview

Ergonomic 'T'-style hand-held enclosure with LCD display cut-out and battery compartment options and membrane keypad recess in lid.

- Moulded in high impact ABS
- Large LCD cut-out area (optional)
- Available with or without battery compartment for 2x AA batteries
- Recesses in lid for membrane keypads or overlays
- Removable tilt stand which is suitable for surface mounting supplied as standard
- 2970 series has been designed to meet the requirements of IP54 or additionally, IP65 with the optional gasket accessory



SPECIFICATION	
Materials	Base, lid and tilt stand high impact ABS
Protection class	2970 series has been designed to meet the requirements of IP54 or additionally, IP65 with the optional gasket accessory
Standard colours	Light grey or black
Standard unit includes	Lid, base, tilt stand and screws
Options	EPDM gasket for IP65 seal

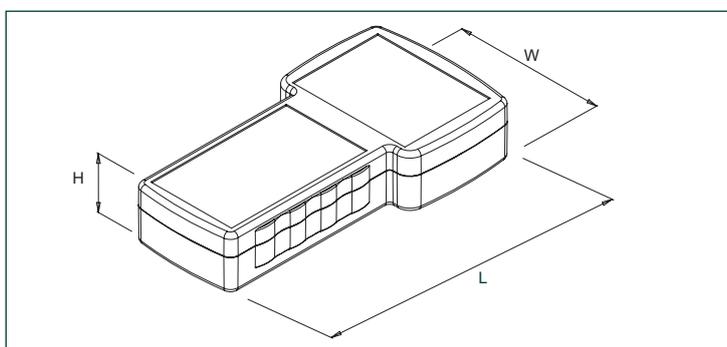

BLACK	LIGHT GREY	LENGTH	WIDTH	HEIGHT	STYLE	
2970-28BS	2970-28GS	210mm	110mm	41mm	-	-
2970-28BO	2970-28GO	210mm	110mm	41mm	cut-out display	-
2970-28BSBC	2970-28GSBC	210mm	110mm	41mm	-	Battery compartment
2970-28BOBC	2970-28GOBC	210mm	110mm	41mm	cut-out display	Battery compartment

KEY FEATURES

LCD display cut-out | Battery compartment | High impact ABS



ACCESSORIES

2970 series IP65 gasket



PART NO.	DESCRIPTION
2970-28GSKT	2970 Series IP65 gasket