


PRESTIGE PRO 8W LED CCT FIRE RATED DOWNLIGHT

SPECIFICATION SHEET

PRODUCT CODE: 793947

Our flagship Pro 8W CCT Fire Rated Downlight is a real trailblazer. Featuring an impressive 900lm output with 4 front adjustable colour temperatures, it also has Flicker Free smooth dimming. Ideal for commercial usage, in offices, Schools, shopping centres & more, this downlight is a great addition to any space. With a 5 year warranty and a 50,000 hour lifespan, the longevity of use with this product is guaranteed.

The Prestige Pro Downlight has additional bezel covers in:
Black: 793954 | Brushed Chrome: 793978
Brass: 793961 | Chrome: 793985

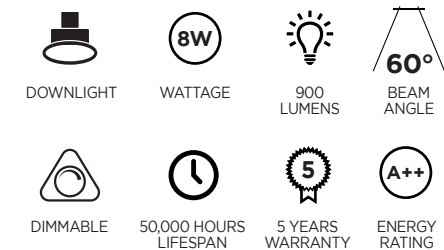



SPECIFICATION

Product code	793947
Fitting	Downlight
Bulb shape	SMD
Wattage	8W
Lumens	900lm
Driver included	Yes
Dimmable	Yes
Beam Angle	60°
Diameter	Ø88mm
Height	63mm
Cut Out Size	Ø68-75mm
Weight	0.2kg
Lifespan	50,000 Hours
Warranty	5 Years
Energy consumption	8kWh/1000h
Material	Aluminum, Iron and Plastic
Packaging	Colour Box
Fire Rated	30, 60, 90 minutes Approved to: BS 476-21: 1987
Manufactured in Accordance To	BS EN 60598:2015, 2-1, 2-2
Acoustics Rated	ISO 10140-2:2010

Voltage	220-240V
Current	80mA
Power	8W
CCT	2700K / 3000K / 4200K / 6000K
Ra	80
Lumens per Watt	112lm/W
Colour Tolerance	±200k
Power Factor	>0.85
Hertz	50/60Hz
Input frequency	50/60Hz
IP Rating	IP65 Front
Energy rating	A++
Insulation Coverage	Loosely Cover with Mineral Wool Insulation

COLOUR TEMP TO LUMENS

2700K	895lm
3000K	925lm
4200K	950lm
6000K	950lm

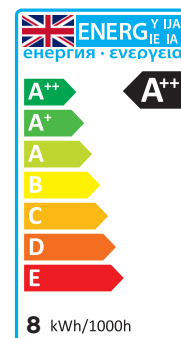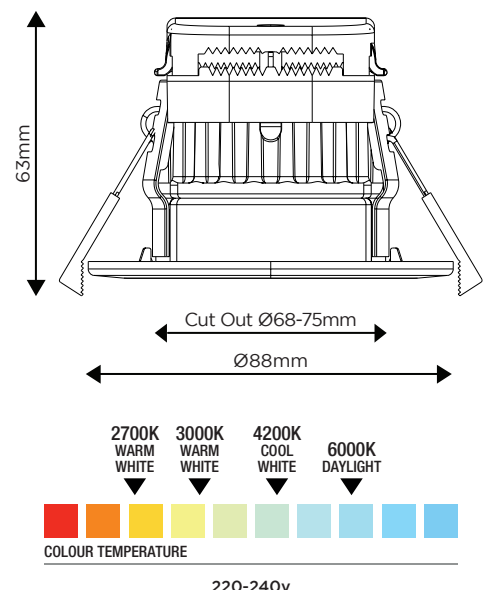

TIME LED is part of Pitacs Limited

Bradbourne Point, Bradbourne Drive, Tilbrook, Milton Keynes, Buckinghamshire MK7 8AT

T: +44 (0)1908 271155 F: +44 (0)1908 640017 E: info@timeled.co.uk W: www.timeled.co.uk

