


SPECIFICATION SHEET

Product Code CCA011

Description 10AX 1 Gang 2 Way Plate Switch

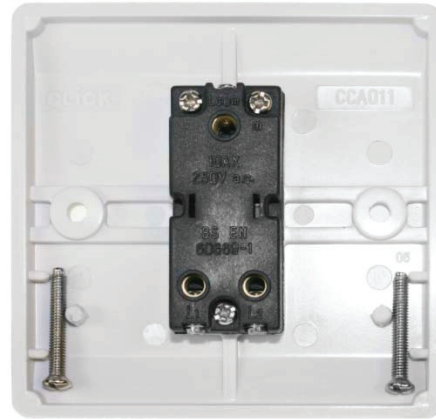

General Information	
Dimensions	86mm x 86mm x 9.5mm
Material composition	Front Plate: Urea Terminals: Brass Terminal Screws: Steel and Yellow Passivated Internal Busbars: Formed Press Brass Silver "On-lay" Copper/Brass Contacts
Back Box Depth	16mm – 47mm
Cable Size	4 x 1.5mm ²
Load Rating	10AX (Suitable for Inductive loads)
Modular	No
Gang	1
2 Way	Yes
Intermediate	No
Warranty	10 Years Domestic

Standards	The Low Voltage Directive 2006/95/EC BS EN 60669– 1:1999 + A1:2002 + A2:2008
-----------	---

Additional Information	Ensure that the mains supply is isolated before commencing installation. Bare earth cables must always be covered with appropriate sleeving and wired to the earth terminal. All white moulded accessories are manufactured using Urea Formaldehyde, which has similar inherent properties to antimicrobial additives that inhibit the growth of infectious diseases. All products independently tested achieved a 99.9% kill rate across all four types of the strains of bacteria – MRSA, E-Coli, Salmonella, and Klebsiella Pneumoniae.
------------------------	--