


## 50.007 PA/BS

Perfect cable gland with spiral top PA7001 PG7 thread length 8, min/max cable dia 3-6.5

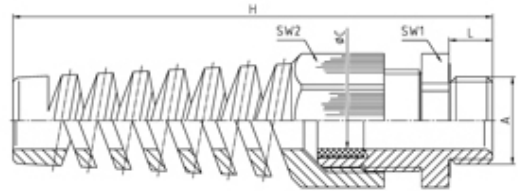

### SPECIFICATION

|                                 |                                        |
|---------------------------------|----------------------------------------|
| Product Type                    | Standard                               |
| Sealing Ring Material           | Polychloroprene-Nitrile rubber CR/NBR  |
| Body Material                   | Polyamide                              |
| Min Temperature Rating °C       | -20                                    |
| Max Temperature Rating °C       | 100                                    |
| IP Rating                       | 68                                     |
| Colour                          | Dark Grey - RAL 7001                   |
| Thread Size                     | PG7                                    |
| Clamping Range Min (mm)         | 3                                      |
| Clamping Range Max (mm)         | 6.5                                    |
| External Connecting Thread Type | PG                                     |
| Thread Length (mm)              | 8                                      |
| Comments                        | details about test standards see annex |
| Width Across Flat 1 (mm)        | 15                                     |
| Width Across Flat 2 (mm)        | 15                                     |
| Height (mm)                     | 63                                     |
| Connecting Thread Size          | Pg 7                                   |
| Additional Material Detail      | Body - Polyamide PA6 V-2               |
| Standards                       | UL514B                                 |
| Test Standard                   | UL 514B                                |