

SPECIFICATION SHEET

GU10 FIRE RATED DOWNLIGHTS - DIE CAST - FIXED

The GU10 Fire Rated Downlights are available as a fixed and tilt option and in a variety of finishes.

Applications:

- Educational Providers • Leisure Centres • Residential



Image shown FGFBDC

Specification

Lamp (not included): GU10 Halogen/CFL/LED
(Aluminium reflector when using halogen)


Material: Die cast aluminium bezel and steel can

Guarantee: 1 Year

Additional Information

- Cut out: Ø: 75mm
- Insulation cap available - CODE 'ICCAP'
- Integrated intumescent material completely seals the downlight in the event of a fire.
- Tested to BS 476 Part 21, 22 and 23 (fire rating), suitable for 30, 60 and 90 minute fire rated ceilings.
- Do not cover with insulation unless fitted with the ICCAP

Dimensions

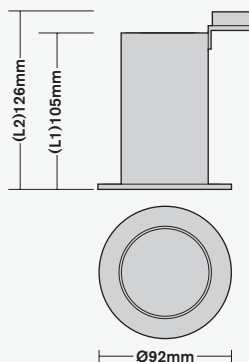

Code	Wattage	Colour	Dimensions (Ø x L1 x L2 mm)
FGFWDC	50W Max.	White	92 x 105 x 136
FGFSDC	50W Max.	Satin Chrome	92 x 105 x 136
FGFCDC	50W Max.	Chrome	92 x 105 x 136
FGFBDC	50W Max.	Brass	92 x 105 x 136
FGFBDCDC	50W Max.	Black Chrome	92 x 105 x 136