

SPECIFICATION SHEET

EMERGENCY LED TWIN SPOT

The 5W LED Emergency Twin Spot with a lightweight polycarbonate body for easy mounting and installation. Three LED indicators provide visual confirmation of the status of the fitting.

Applications

• Commercial Sites • Warehouses • Retail



Specification

LED: 2 x 40 LEDs (2.6W Per Head)

Material: Polycarbonate

Lumen Output: 460lm

Colour Temperature: 6000K-7000K

Guarantee: 1 Year

Life Expectancy: 40,000 Hours


Working Temperature: 0°C - 40°C

Power Factor: 0.91

Additional Information

- 3 Hours emergency duration.
- 3V Deep discharge protection.
- 4.3V Overcharge protection.
- Ø20mm Cable entry hole size.
- 24 Hours charging time.
- Class one safety classification.
- CE certified.
- Ni-Cd D3.6V 4500mAH Battery included.
- Weight: 1143g.

Dimensions

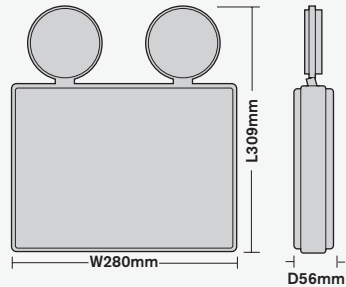

Code	Wattage	Dimensions (L x W x D mm)
LF292E	5.2W	309 x 280 x 56