



CorePro GLASS LED candles and lustres



CorePro LEDLusterND2-25W P45 E14 827 CLG

Featuring a classic heritage design, Classic filament LED lamps combine the familiar shapes of classic incandescent bulbs with the benefits of the long-lasting LED technology. An very easy choice for people who are looking for the replacement for retrofit LED candles and lustres: compared to convential lamps, it provides a 90% energy saving. CorePro Glass LED candles and lustres provide excellent quality of light. By offering a lifetime of 15,000 hours, they reduce maintenance costs.

Product data

General Information	
Cap base	E14 [E14]
EU RoHS compliant	Yes
Nominal lifetime (nom.)	15000 h
Switching cycle	20,000X
Technical type	2-25W
	Sphere
Light Technical	
Colour Code	827 [CCT of 2,700 K]
Luminous flux (nom.)	250 lm
Colour designation	Warm white (WW)
Correlated Colour Temperature (Nom)	2700 K
Luminous efficacy (rated) (nom.)	125.00 lm/W
Colour consistency	<6
Colour rendering index (nom.)	80
LLMF at end of nominal lifetime (nom.)	70 %


Operating and Electrical	
Input frequency	50 to 60 Hz
Power (Rated) (Nom)	2 W
Lamp current (nom.)	20 mA
Wattage equivalent	25 W
Starting time (nom.)	0.5 s
Warm-up time to 60% light (nom.)	0.5 s
Power factor (nom.)	0.4
Voltage (Nom)	220-240 V
Temperature	
T-Case maximum (nom.)	36 °C
Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Lamp Finish	Clear

CorePro GLASS LED candles and lustres

Bulb shape	P45 [P 45mm]
Approval and Application	
Energy Efficiency Class	E
Energy consumption kWh/1,000 hours	2 kWh
	387363
Product Data	
Full product code	871951434774800

Order product name	CorePro LEDLusterND2-25W P45 E14 827 CLG
EAN/UPC – product	8719514347748
Order code	34774800
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
SAP material	929001238692
SAP net weight (piece)	0.014 kg


Dimensional drawing

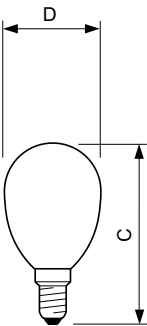


CorePro LEDLusterND2-25W P45 E14 827 CLG

Product	D	C
CorePro LEDLusterND2-25W P45 E14 827 CLG	45 mm	80 mm

Photometric data

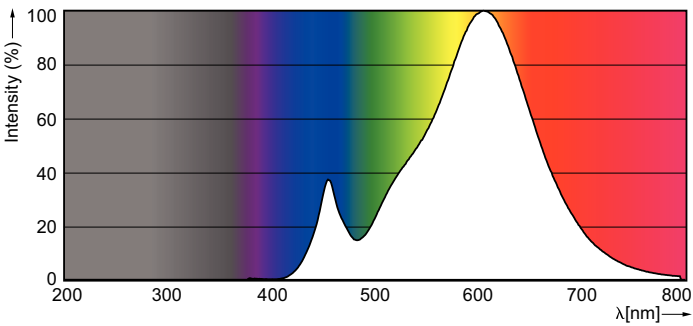


LED Lamps,Lightcolour /827 ND CL

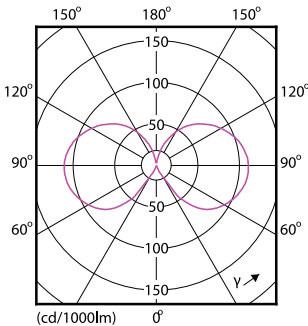

Classic LEDCandle ND 2-25W P45 827 CL


CorePro GLASS LED candles and lustres

Photometric data

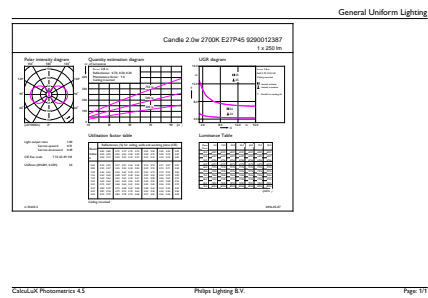


Classic LEDCandle ND 2-25W P45 827 CL

Lifetime

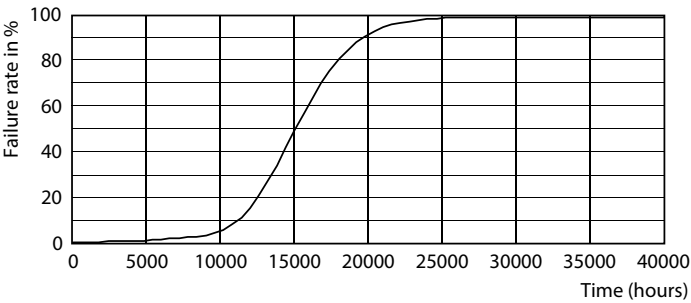

15K LED

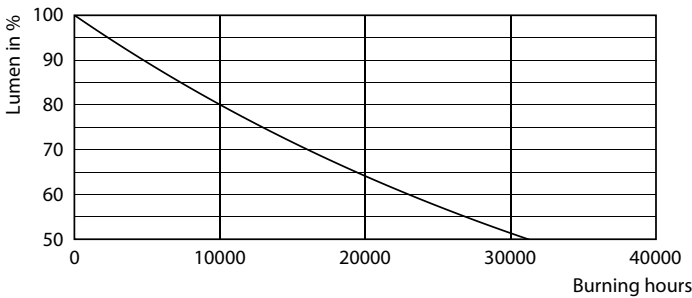

15K LMP

