




# Product data sheet

Power tools for trade & industry

High-pressure Washer

## GHP 5-13 C

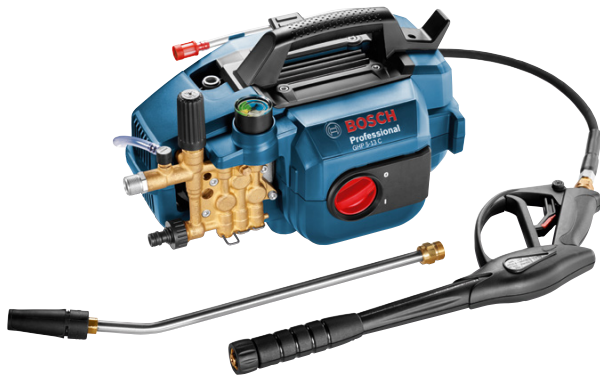

Compact and powerful

### The most important data

Operating pressure	130 bar
Max. pressure	140 bar
Rated input power	2,300 W

**Part Number** 0 600 910 070

[> More product information](#)

## Technical data

### Technical data

Max. pressure	140 bar
Rated input power	2,300 W
Operating pressure	130 bar
Max. inlet temperature	50 °C
Cable length	5 m
Hose length	8 m
Weight (without accessories)	16.5 kg
Max. flow rate	520 l/h
Pump system	Crankshaft
Pistons	Triple Ceramic-coated stainless steel
Motor type	Induction
Packaging dimensions (width x length x height)	341 x 518 x 283 mm
Voltage, electrical	240 V



**BOSCH**

Invented for life

# Product data sheet

Power tools for trade & industry

---

## Advantages:

- Efficient: excellent power-to-weight ratio to complete cleaning jobs quickly
  - Long service life: sturdy and reliable, crankshaft-driven brass pump with ceramic-coated pistons
  - Adaptable: variable pressure for optimal flexibility
-