


DRAM MEMORY MODULE SPECIFICATION

- > Lifetime Warranty
- > Delivered in Anti-Static Packaging

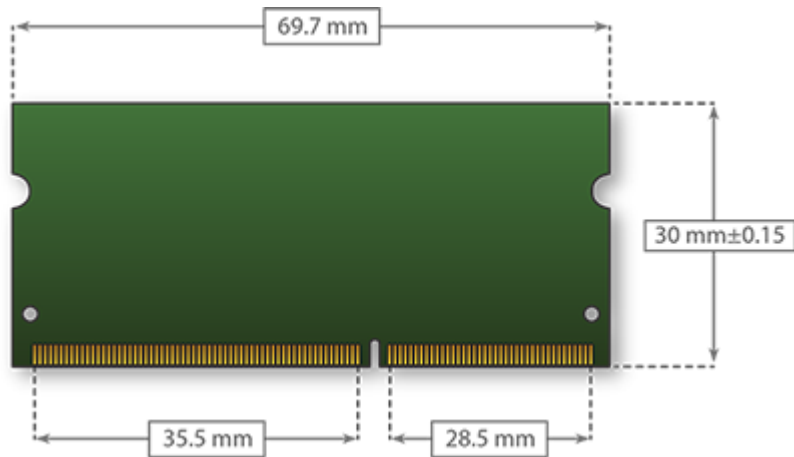

INTEGRAL Part Number	IN4V4GNEUSX
Description	4GB LAPTOP RAM MODULE DDR4 2666MHZ PC4-21300 UNBUFFERED NON-ECC SODIMM 1.2V 512x16 CL19 INTEGRAL
Category	NOTEBOOK
Form Factor	260pin SODIMM
Density	4GB
DRAM Technology	DDR4
Speed	PC4-21300 / 2666 MHz
Depth	512Mbit
Width	X64bit
Buffering	UNBUFFERED
Error Correction	NON-ECC
CAS Latency	19 CYCLES
Voltage	1.2 V
Rank	1
Profile	STANDARD
DRAM IC Configuration	512Mbit X 16bits
DRAM IC Count	4 Chips
DRAM IC Package	FBGA
DRAM IC Placement	SINGLE SIDED
Note	