

CONSTANT VOLTAGE LED DRIVER

24VDC 250WATT



STONTRONICS: LED-DR-24V-250W-IP67

Features:

- Input Voltage 200-277vac
- IP67 Rated
- Low Profile
- Compact Plastic Low Profile enclosure
- 1 Year Warranty



Description:

The Range of 250 Watt Constant Voltage LED Drivers are housed in a compact light weight high quality IP67 plastic enclosure with covered input & output terminals suitable for general Indoor LED applications

Specification	
Part Number	LED-DR-24V-250W-IP67
Output Voltage Rating	24 Vdc
Output Current	10.4A
Rated Power	250 Watt
Dimensions	220.8 x 61.5 x 36 mm
Input Voltage Range	200-277VAC
Input Voltage Frequency	50Hz/60Hz
Inrush Current	<75A
input power	< 280W
Efficiency	≥ 90 %
Power Consumption Without Load	<0.5W
Overload Protection	Ta ,0.94-1.06 times of input voltage, 1.2 times of rated power
Short Circuit Protection	Ta ,0.94-1.06 times of input voltage
Automatically Restart	Over load, short circuit revocation
Working Temperature	-40°C to +50°C
Relative Humidity	45%-95%
MTBF	50000hr
EMI emission	EN55015
EMS Standards	EN61000-4-2,3,4,5,6; EN61547
Safety Standards	EN61347-1, EN61347-2-13

General Note

TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.

STONTRONICS

TT Electronics IoT Solutions Ltd
Tofts Farm East, Brenda Road, Hartlepool, TS25 2BQ, UK
t: +44 (0) 1429 852 500


CONSTANT VOLTAGE LED DRIVER

24VDC 250WATT

STONTRONICS: LED-DR-24V-250W-IP67



Diagrams

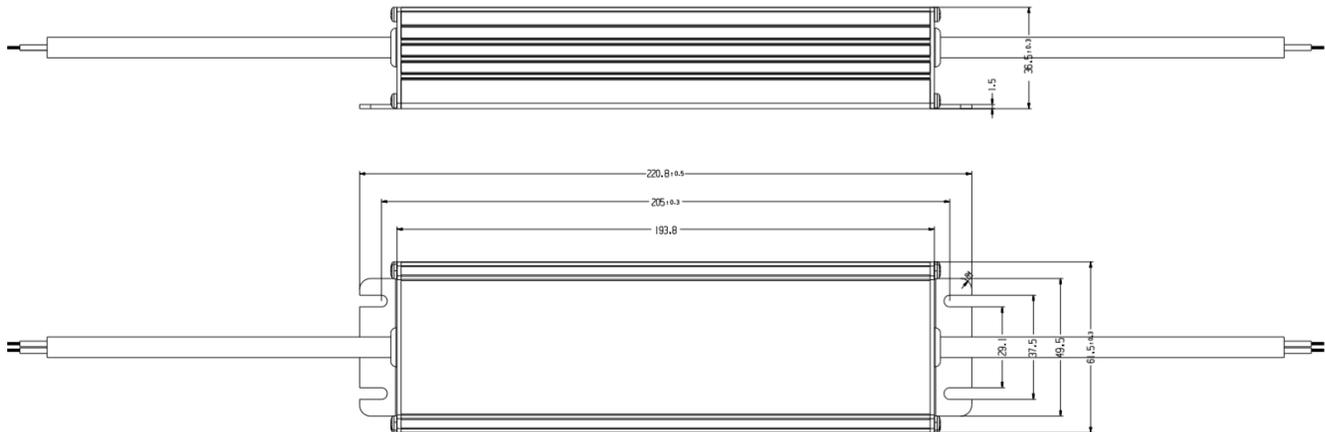

Wiring Diagram

