


14 - Stand Alone Racks

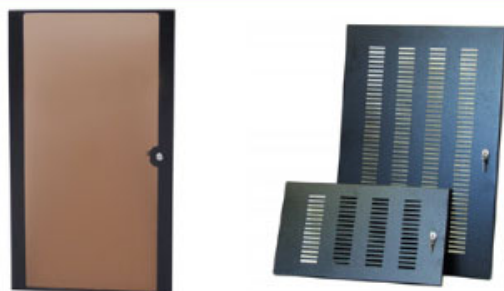

Contractor Front Doors

Locking Front Doors for the Contractor Rack series are available in Smoked Gray Polycarbonate or Vented Steel. They come fully assembled with barrel locks and 2 keys, and can be retro fitted after installation. Replacement keys are available as they are keyed alike.

Material: Steel/Polycarbonate

Lockable Smoked Polycarbonate Doors

Part No.	Size (U)
PGRD06C	6U
PGRD08C	8U
PGRD12C	12U
PGRD12C-300	12U - For 300 Series Enclosures
PGRD16C	16U
PGRD16C-300	16U - For 300 Series Enclosures
PGRD20C	20U
PGRD24C	24U
PGRD28C	28U
PGRD32C	32U
PGRD35C	35U

Lockable Vented Doors

Part No.	Size (U)
RD06C	6U
RD08C	8U
RD12C	12U
RD16C	16U
RD20C	20U
RD24C	24U
RD28C	28U
RD32C	32U
RD35C	35U

Accessories

Part No.	Size (U)
DL01	Replacement Barrel Lock & Key

Contractor Castor Base Kit



Castor Base kit for Contractor Racks, Wood Shell Racks and Credenza Racks.

Comprises of 4 Heavy Duty 70mm/2.76" Castors with fixings.
Contractor Castor Base Kit includes MDF load bearing panels
Max Load Rating: 150Kg/330.69Lb

Material: Steel

Part No.	Description	Load Capacity
RCB-600	Castor Base Kit for Contractor Racks	150Kg/330.69Lb
RCB-600B	Breaked Castor Base Kit for Contractor Racks	150Kg/330.69Lb
RCBWR	Castor Base Kit for Wood & Wood Shell Racks	150Kg/330.69Lb
CZRCB	Castor Base Kit for Credenza Racks	150Kg/330.69Lb

RSP Contractor Rear Panels **NEW!**



Slam shut rear panel system for Contractor racks.

Comprises of 3 sizes that work together to make up to all rack sizes in the range.

All panels are vented and include a 1U space for Blank, Vented or Cable Access Rack panels.

Material: Steel

Part No.	Size (U)
RSP06	6U
RSP08	8U
RSP12	12U