

AH15

ACTIVE COMPACT WEATHERPROOF HORN SPEAKER

Item ref: 952.103UK



User Manual



Caution: Please read this manual carefully before operating
Damage caused by misuse is not covered by the warranty

The AH15 is a robust, weatherproof horn speaker with a built-in amplifier, which can be installed indoors or outdoors onto a wall or other surface from its adjustable mounting bracket.

Follow the wiring guide below for power and signal connections to the 4-core cable (connections should be sealed or sheltered from the elements)

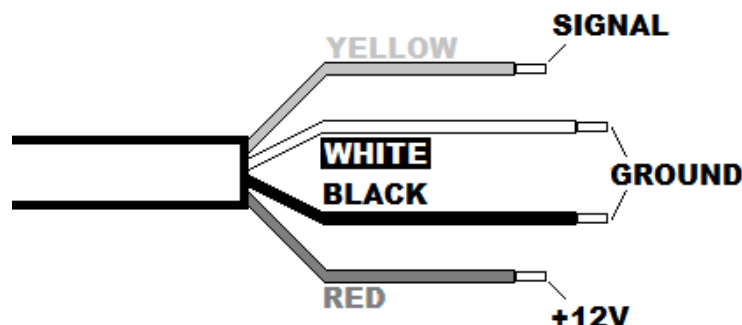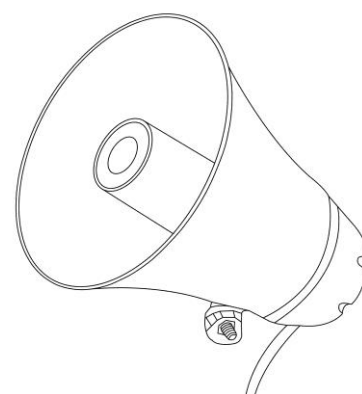

The amplifier can be operated from any 12Vdc power supply capable of delivering up to 1.2A current.

Connect the Line Level Audio (0dB = 0.775Vrms) input to the yellow wire and Ground to the white wire (signal & power ground are common)

Connect +12V to the red wire and connect the Ground to the black wire.

Specifications

Power supply	12Vdc, 1.2A (not included)
Construction	ABS moulded body, metal bracket
Connection	Hard-wired cable (power + line in)
Output power: max.	15W
IP rating	IP66
Dimensions	165 x 140mmØ
Weight	446g



Disposal: The "Crossed Wheelie Bin" symbol on the product means that the product is classed as Electrical or Electronic equipment and should not be disposed with other household or commercial waste at the end of its useful life. The goods must be disposed of according to your local council guidelines.

Errors and omissions excepted. Copyright© 2021.

AVSL Group Ltd. Unit 2-4 Bridgewater Park, Taylor Rd. Manchester. M41 7JQ

AVSL (EUROPE) Ltd, Unit 3D North Point House, North Point Business Park, New Mallow Road, Cork, Ireland