

# Boxes

mkelectric.co.uk



## Moulded Boxes

32MM  
SURFACE



**2140WHI** 10  
FOR 1 GANG  
POWER ACCESSORIES  
SQUARE CORNERS

Knockouts are provided in base and sides for cable entry

### DIMENSIONS

1 gang: 87 x 87mm  
2 gang: 87 x 148mm

### FIXING CENTRES

1 gang: 60.3mm  
2 gang: 120.6mm  
BS 5733:2010

44MM  
SURFACE



**2031WHI** 10  
FOR 1 GANG  
POWER ACCESSORIES  
SQUARE CORNERS

Knockouts in base and sides for cable entry.


### DIMENSIONS

87 x 87mm

### FIXING CENTRES

60.3mm  
BS 5733:2010

DRY LINING  
35MM  
FLUSH

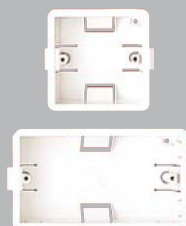

**QFB1WHI** 20  
1 GANG  
**QFB2WHI** 10  
2 GANG

All round flange for a flush fit. One piece moulded lug automatically snaps into place. No rear projections. Clamp device on cable entry. Will accommodate partition thickness between 6mm and 16mm. Earth terminal facility.  
BS 4662:2006




**QFB/IG1** 20  
1 GANG WITH  
INTUMESCENT GASKET  
**QFB/IG2** 10  
2 GANG WITH  
INTUMESCENT GASKET

### QFB/IG1 & QFB/IG2

Pre-fitted with intumescent gaskets to give fire protection, in accordance with BS 476-2:1987. In a fire situation, a chemical reaction will occur with the intumescent material. The void behind the wiring device will be filled, providing protection against the passage of fire.  
BS 4662:2006

MI CABLE BOXES  
37MM  
SURFACE

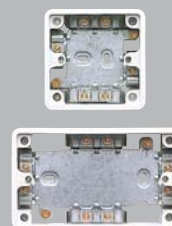

**K2131WHI** 5  
1 GANG  
10 CLAMPS  
**K2132WHI** 5  
2 GANG  
12 CLAMPS

Clamps accept 20mm sealing pots.

### DIMENSIONS

1 gang: 92 x 92mm  
2 gang: 92 x 152mm

### FIXING CENTRES

1 gang: 60.3mm  
2 gang: 120.6mm  
BS 5733:2010

DUAL BOX  
38MM  
SURFACE



**K2025WHI** 5  
FOR MOUNTING  
TWO 1 GANG  
LOGIC PLUS™  
ACCESSORIES

This box has two slots in base with 60.3mm and 120.6mm fixing centres for fitting over BS 4226 flush boxes. Knockouts provided for cable entry.  
Includes integral dividing fillet.

**DIMENSIONS**  
86 x 172 mm  
BS 5733:2010

40MM  
SURFACE



**K2031WHI** 10  
FOR 1 GANG  
LOGIC PLUS™  
POWER ACCESSORIES  
**K2172WHI** 5  
FOR 2 GANG  
LOGIC PLUS™ 50 AMP  
DP SWITCHES

Knockouts provided in sides and base.

**K2172:** Earth terminal fitted in base of box.

### DIMENSIONS

K2031: 87 x 87mm  
K2172: 87 x 148mm

### FIXING CENTRES

K2031: 60.3mm  
K2172: 120.6mm  
BS 5733:2010


FLANGE BOXES  
45MM  
FLUSH



**K2061WHI** 5  
1 GANG  
**K2062WHI** 5  
2 GANG

**DIMENSIONS**  
K2061: 88 x 88mm  
K2062: 88 x 148mm  
**FIXING CENTRES**  
K2061: 60.3mm  
K2062: 120.6mm  
BS 5733:2010

Mounting  
Pattresses  
SURFACE

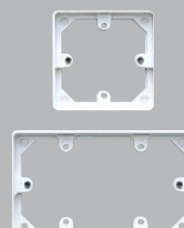

**K2134WHI** 10  
1 GANG 20MM DEEP  
FOR LOGIC PLUS™  
ACCESSORIES  
**K2133WHI** 10  
2 GANG 20MM DEEP  
FOR LOGIC PLUS™  
ACCESSORIES

### FIXING CENTRES

1 gang: 60.3mm  
2 gang: 120.6mm  
BS 5733:2010